
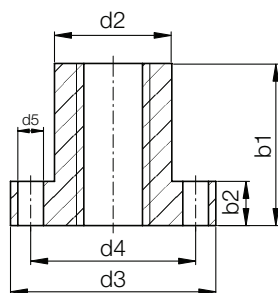



drylin® Lead Screw Drives | Product Range

Trapezoidal lead screw nuts with flange, made from iglidur® W300, left-hand thread

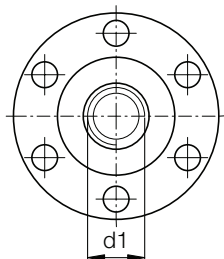

Order key

WFLM-2525TR10x2

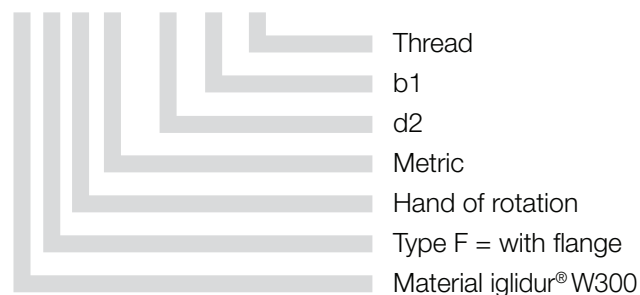

Dimensions [mm]

Part number	Effective supporting surface [mm ²]	d2	d3	d4	d5	b1	b2	Thread d1 x P	max. stat. F axial [N]
		h9							
WFLM-2525TR10x2	352	25	42	34	5	25	10	TR10x2	1,760
WFLM-2835TR12x3	576	28	48	38	6	35	12	TR12x3	2,880
WFLM-2835TR14x4	658	28	48	38	6	35	12	TR14x4	3,290
WFLM-2835TR16x2	822	28	48	38	6	35	12	TR16x2	4,110
WFLM-2835TR16x4	768	28	48	38	6	35	12	TR16x4	3,840
WFLM-2835TR18x4	878	28	48	38	6	35	12	TR18x4	4,390
WFLM-3244TR20x4	1,242	32	55	45	7	44	12	TR20x4	6,210
WFLM-3244TR24x5	1,484	32	55	45	7	44	12	TR24x5	7,420
WFLM-3846TR26x5	1,696	38	62	50	7	46	14	TR26x5	7,900*
WFLM-3846TR28x5	1,840	38	62	50	7	46	14	TR28x5	5,900*
WFLM-3846TR30x6	1,948	38	62	50	7	46	14	TR30x6	4,470*

* reduced axial load due to nut geometry

delivery from stock
timeprices price list online
www.igus.eu/eu/wflm