

For new constructions:
Series "E2 Tubes"
R68 ▶ page 6.34


Series R68 classic E2 Tubes

45

igus® E-ChainSystems®


Phone +49- (0) 22 03-96 49-800
Fax +49- (0) 22 03-96 49-222

igus® GmbH
51147 Cologne

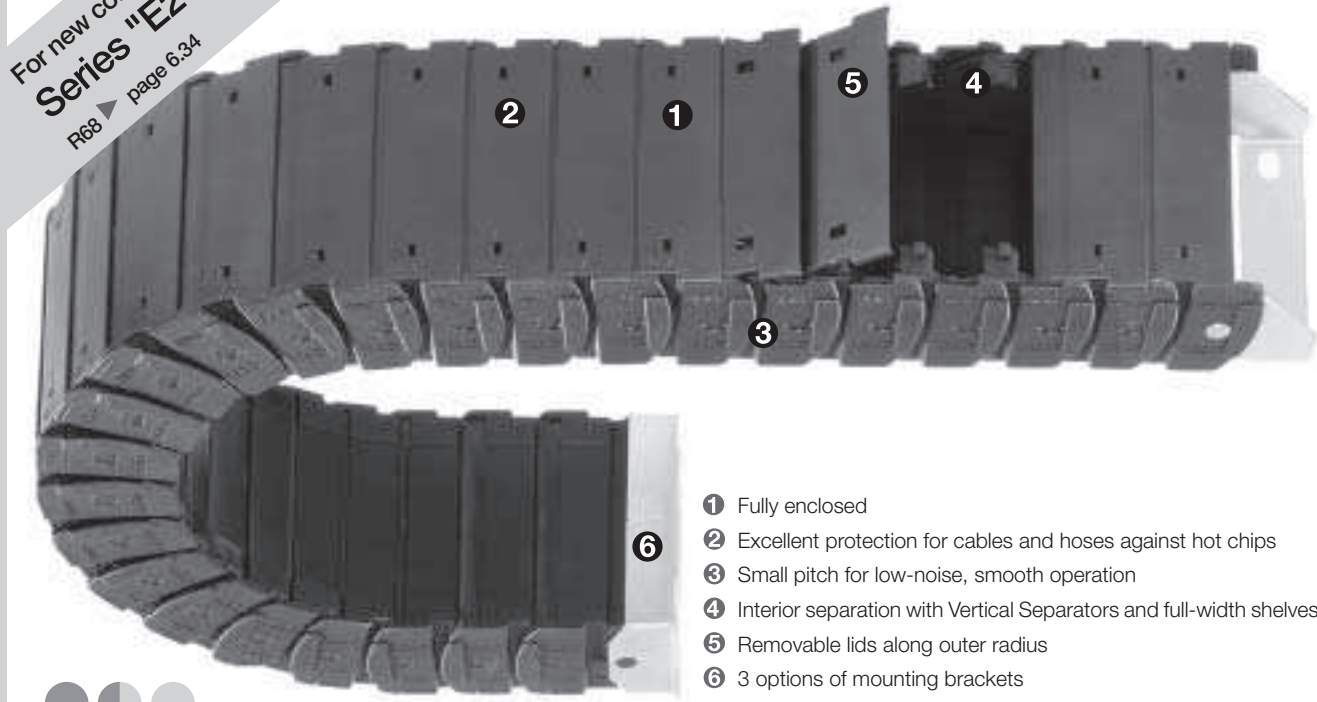

- ① Fully enclosed
- ② Excellent protection for cables and hoses against hot chips
- ③ Small pitch for low-noise, smooth operation
- ④ Interior separation with Vertical Separators and full-width shelves
- ⑤ Removable lids along outer radius
- ⑥ 3 options of mounting brackets

● ● ● Price index


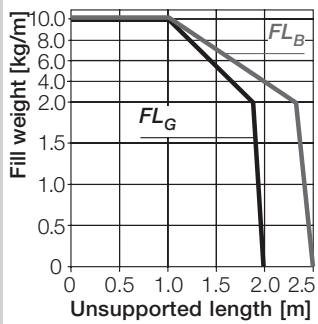


Length of travel S [m]
0 1 2 3 4 5

Unsupported length

FL_G = with straight upper run

FL_B = with permitted sag

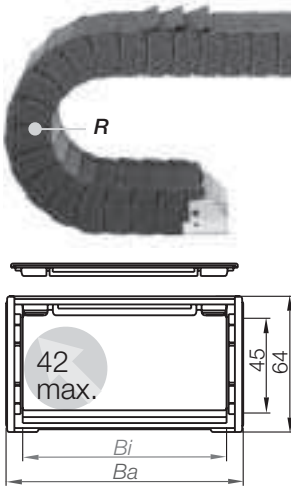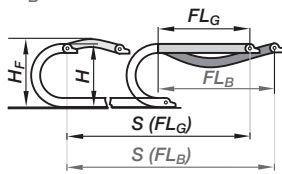


R68 classic - snap-open along outer radius

Part No.	Bi [mm]	Ba [mm]	R [mm]	Bending Radii
68.1. <input type="text"/> .0	75	93	100	125 150
68.2. <input type="text"/> .0	115	133	200	225 250
68.3. <input type="text"/> .0	175	196	300	
Radii for all widths!				


Completare con il raggio desiderato (R) es. 68.1. 125.0

Bending radii listed above can be combined with every tube width!

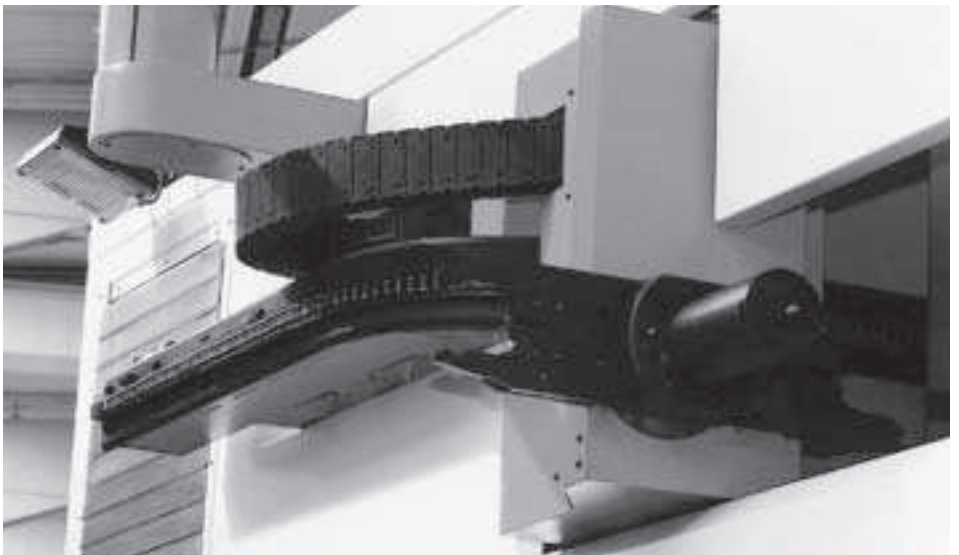

Series R68 classic - fully enclosed E-Tube

Part No. structure

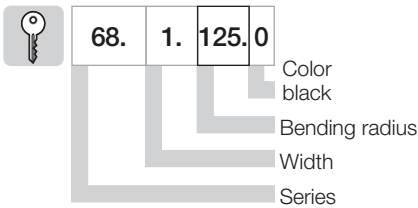

Order example 3,0 m complete E-Tube
(indicate tube-lengths or number of links)

- 3,0 m (84 links) **Series 68.1.125.0**
- + 2 separators **311** assembled each 2nd link
- + 1 set mounting brackets **681.12**