


igus® E-ChainSystems®


Phone +49- (0) 22 03-96 49-800
Fax +49- (0) 22 03-96 49-222

igus® GmbH
51147 Cologne

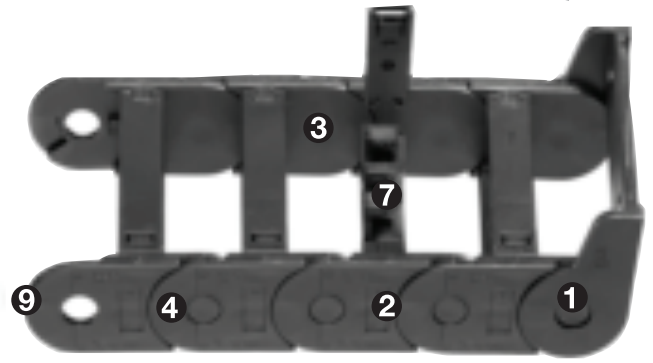

- ① Large pins for long service life
- ② Double stop dog for long unsupported length
- ③ Space-saving ratio of inner-to-outer dimensions
- ④ Lateral glide surfaces for side-mounted operation
- ⑤ Cable-friendly, smooth interior
- ⑥ Series 27i snap-open along inner radius can be combined with Series 27 snap-open along outer radius, accessible from the top
- ⑦ Modular interior separation
- ⑧ Integrated strain relief possible
- ⑨ Side wear pads





● ● ● Price index

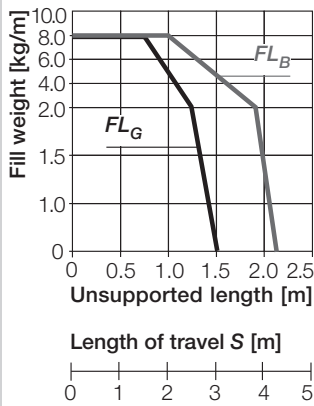

Unsupported length

FL_G = with straight upper run

FL_B = with permitted sag

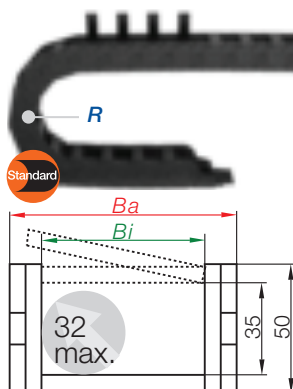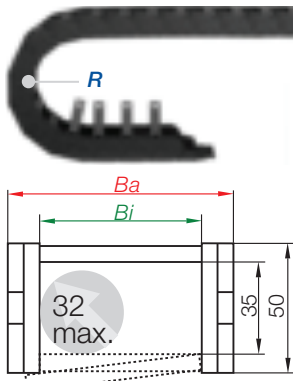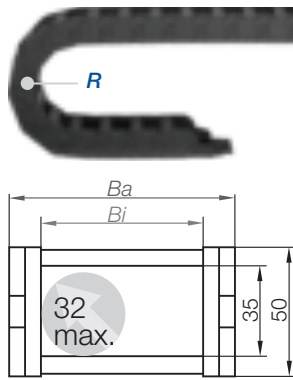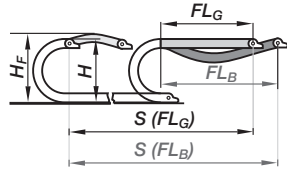

Series 26 - non snap-open

Part No.	B_i [mm]	B_a [mm]	R [mm] Bending Radii
26.05.□.0	50	66	063 075 100
26.07.□.0	75	91	125 150 175
26.10.□.0	100	116	200 250
26.12.□.0	125	141	Radii for all widths!
26.15.□.0	150	166	
26.17.□.0	175	194	
26.20.□.0	200	219	

Supplement Part No. with required radius. Example: 26.10.100.0

Bending radii listed above can be combined with every chain width!

Series 27i - snap-open along inner radius

Part No.	B_i [mm]	B_a [mm]	R [mm] Bending Radii
27i.05.□.0	50	66	063 075 100
27i.07.□.0	75	91	125 150 175
27i.10.□.0	100	116	200 250
27i.12.□.0	125	141	Radii for all widths!
27i.15.□.0	150	166	
27i.17.□.0	175	194	
27i.20.□.0	200	219	

Supplement Part No. with required radius. Example: 27i.10.100.0

Bending radii listed above can be combined with every chain width!


Series 27 - snap-open along outer radius

Part No.	B_i [mm]	B_a [mm]	R [mm] Bending Radii
27.05.□.0	50	66	063 075 100
27.07.□.0	75	91	125 150 175
27.10.□.0	100	116	200 250
27.12.□.0	125	141	Radii for all widths!
27.15.□.0	150	166	
27.17.□.0	175	194	
27.20.□.0	200	219	

Supplement Part No. with required radius. Example: 27.10.100.0

Bending radii listed above can be combined with every chain width!

Part No. structure

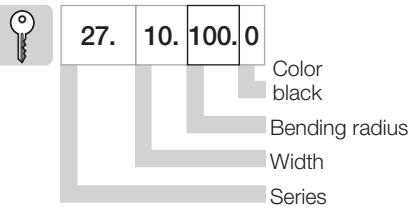

Order example 3,0 m complete E-Chain®
(indicate chain-lengths or number of links)

3,0 m (54 links) Series 27.10.100.0

+ 2 separators 261 assembled each 2nd link

+ 1 set mounting brackets + tiwrap plates 2610.34.PZB