


igus® E-ChainSystems®


Phone +49- (0) 22 03-96 49-800
Fax +49- (0) 22 03-96 49-222

igus® GmbH
51147 Cologne

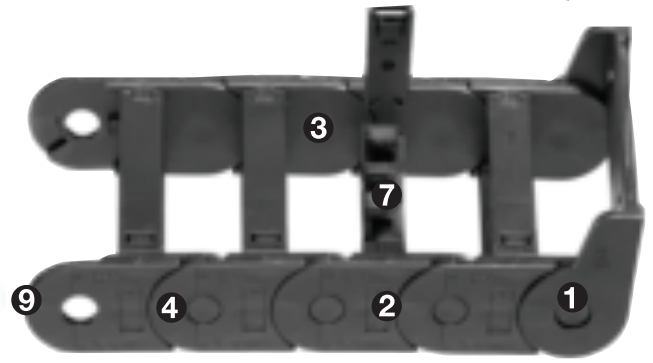

- ① Large pins for long service life
- ② Double stop dog for long unsupported length
- ③ Space-saving ratio of inner-to-outer dimensions
- ④ Lateral glide surfaces for side-mounted operation
- ⑤ Cable-friendly, smooth interior
- ⑥ Series 27i snap-open along inner radius can be combined with Series 27 snap-open along outer radius, accessible from the top
- ⑦ Modular interior separation
- ⑧ Integrated strain relief possible
- ⑨ Side wear pads





● ● ● Price index

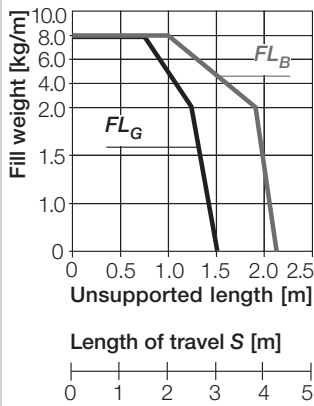

Unsupported length

FL_G = with straight upper run

FL_B = with permitted sag

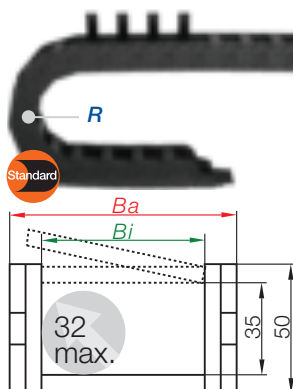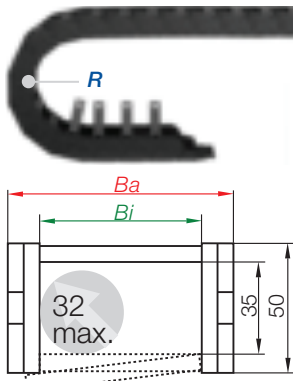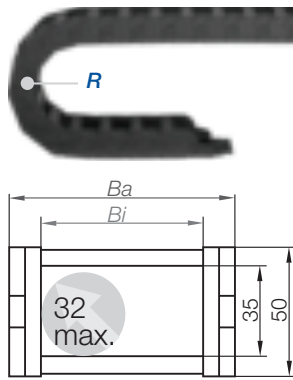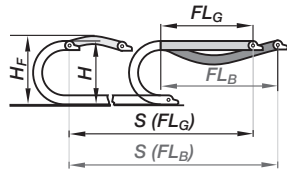

Series 26 - non snap-open

Part No.	B_i [mm]	B_a [mm]	R [mm] Bending Radii
26.05.□.0	50	66	063 075 100
26.07.□.0	75	91	125 150 175
26.10.□.0	100	116	200 250
26.12.□.0	125	141	Radii for all widths!
26.15.□.0	150	166	
26.17.□.0	175	194	
26.20.□.0	200	219	

Supplement Part No. with required radius. Example: 26.10.100.0

Bending radii listed above can be combined with every chain width!

Series 27i - snap-open along inner radius

Part No.	B_i [mm]	B_a [mm]	R [mm] Bending Radii
27i.05.□.0	50	66	063 075 100
27i.07.□.0	75	91	125 150 175
27i.10.□.0	100	116	200 250
27i.12.□.0	125	141	Radii for all widths!
27i.15.□.0	150	166	
27i.17.□.0	175	194	
27i.20.□.0	200	219	

Supplement Part No. with required radius. Example: 27i.10.100.0

Bending radii listed above can be combined with every chain width!


Series 27 - snap-open along outer radius

Part No.	B_i [mm]	B_a [mm]	R [mm] Bending Radii
27.05.□.0	50	66	063 075 100
27.07.□.0	75	91	125 150 175
27.10.□.0	100	116	200 250
27.12.□.0	125	141	Radii for all widths!
27.15.□.0	150	166	
27.17.□.0	175	194	
27.20.□.0	200	219	

Supplement Part No. with required radius. Example: 27.10.100.0

Bending radii listed above can be combined with every chain width!

Part No. structure

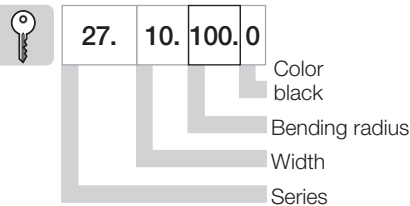

Order example 3,0 m complete E-Chain®
(indicate chain-lengths or number of links)

3,0 m (54 links) Series 27.10.100.0

+ 2 separators 261 assembled each 2nd link



+ 1 set mounting brackets + tiwrap plates 2610.34.PZB

Pitch = 56 mm Links per m = 18 Chain length = $S/2 + K$


R	063	075	100	125	150	175	200	250
H ⁺⁴	180	200	250	300	350	400	450	550
D	140	150	175	200	225	250	275	325
K	335	375	475	550	650	750	825	925

The required clearance height is $H_F = H + 35$ mm (with 2,0 kg/m fill weight). Please consult igus® if space is particularly restricted.

Installation Dimensions

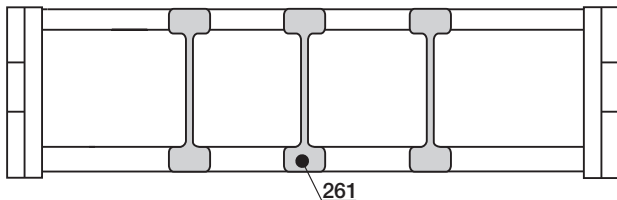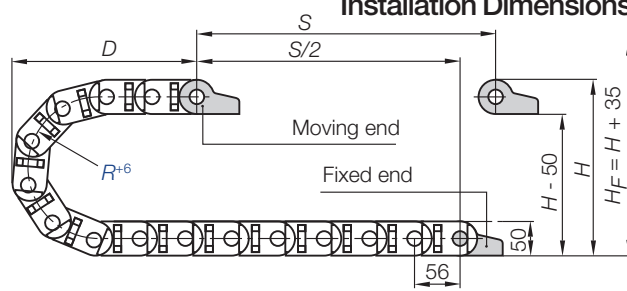

Vertical separator	
unassembled	260
assembled	261

 

Interior Separation

Full program ▶ page 5.118




26...3.PZ(B)

Moving end


26...4.PZ(B)

Fixed end

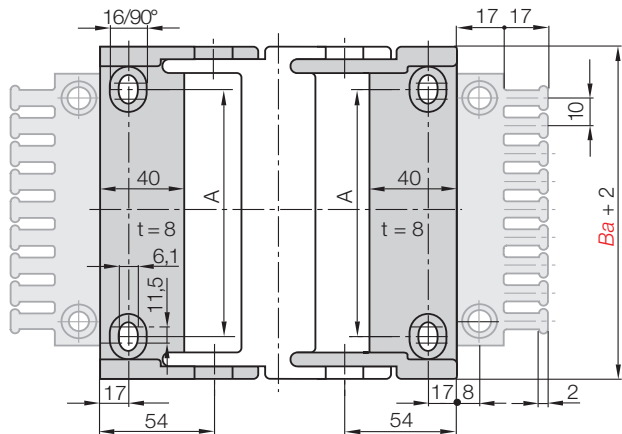


Moving end (with bore)

26...3.PZ(B)

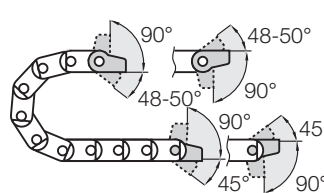

26...4.PZ(B)
Fixed end (with pin)

Mounting Brackets

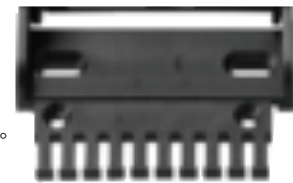

Polymer pivoting, with or without strain relief tiwrap plates

For E-Chain®	Part No. full set with tiwrap plate	Part No. with tiwrap plate + 10 cable tiwraps	Part No. full set without tiwrap plate	Dimension A [mm]
26/27/27i.05. ▶	2605.34.PZB	2605.34.PZBK1	2605.34.PZ	30
26/27/27i.07. ▶	2607.34.PZB	2607.34.PZBK1	2607.34.PZ	55
26/27/27i.10. ▶	2610.34.PZB	2610.34.PZBK1	2610.34.PZ	80
26/27/27i.12. ▶	2612.34.PZB	2612.34.PZBK1	2612.34.PZ	105
26/27/27i.15. ▶	2615.34.PZB	2615.34.PZBK1	2615.34.PZ	130
26/27/27i.17. ▶	2617.34.PZB	2617.34.PZBK1	2617.34.PZ	155
26/27/27i.20. ▶	2620.34.PZB	2620.34.PZBK1	2620.34.PZ	180

Tiwrap plates are possible at the moving end and/or the fixed end!

Part No. structure

2605.34.PZ B



Full set with tiwrap plate
Full set without tiwrap plate

Full set, for both ends:

2605. 34. PZB (+ tiwrap plates)

Single-part order:

2605. 3. PZB (+ tiwrap plates)

Mounting bracket with bore

2605. 4. PZB (+ tiwrap plates)

Mounting bracket with pin



Interior separation with full-width shelves and shelves possible

Polymer mounting bracket, locking

KMA mounting bracket available with C-profile

Additional Features

For more features ▶ see link below



E2 medium classic
Inner height: 35 mm

Phone +49- (0) 22 03-96 49-800
Fax +49- (0) 22 03-96 49-222



chapter 10



chapter 9