


Option KMA* - pivoting

- Pivoting
- Short and long travels
- Space-restricted
- Corrosion-resistant
- Pivoting option at fixed end available upon request (Part No. 11800...12)


*KMA = Polymer Metal Mounting Bracket

Moving end (outer link)
11800...1

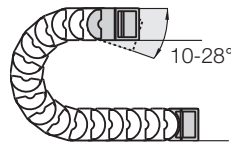

11800...4


Fixed end (inner link)

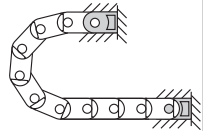

Mounting bracket attachment

11800...4
Fixed end

11800...1
Moving end

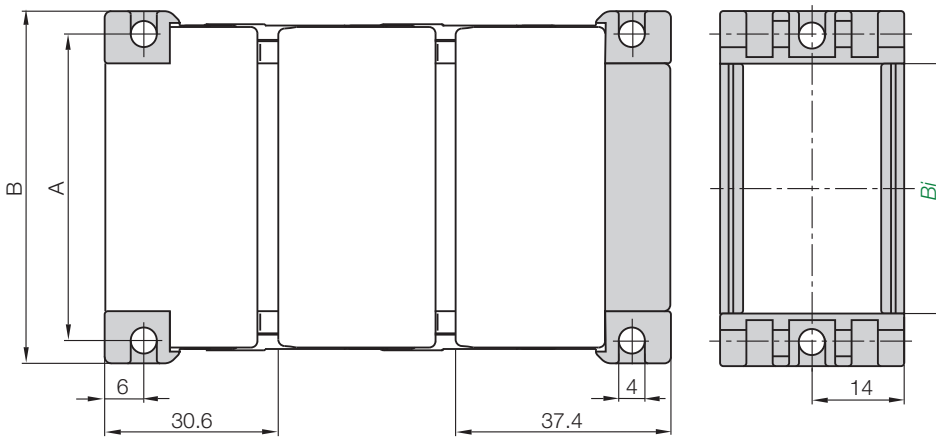


Dimensions and order configurations



The mounting brackets are supplied with hexagon nuts and can be attached with M4 bolts, or the mounting brackets may also be attached with M4 socket head cap bolts.

Part No. structure

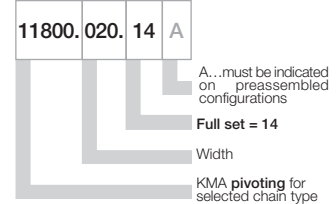

Full set, for both ends:

11800.020.14

Single-part order:

11800.020.1

Mounting bracket with bore

11800.020.4

Mounting bracket with pin

For Series	Part No. full set	Dim. A [mm]	Dim. B [mm]
117-118.020. ▶	11800.020.14	29	36
117-118.025. ▶	11800.025.14	34	41
117-118.038. ▶	11800.038.14	47	54
117-118.048. ▶	11800.048.14	57	64
117-118.063. ▶	11800.063.14	72	79
117-118.080. ▶	11800.080.14	89	96
117-118.100. ▶	11800.100.14	109	116

Please add the Part No. with the requested index - e.g. 11800.048.14

For the preassembled mode please add the index A e.g. 11800.048.14 A

Phone +49- (0) 22 03-96 49-800
Fax +49- (0) 22 03-96 49-222

