


Part No. structure


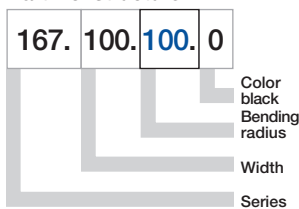


Series R167 - hinged, snap-open on both sides of the inner radius


Part No.	B_i [mm]	B_a [mm]	R [mm]	Bending radii								Weight [kg/m]
167.050.□.0	50	68	100	125	150	175	200	225	250	300	≈ 1,58	
167.075.□.0	75	93	100	125	150	175	200	225	250	300	≈ 1,84	
167.100.□.0	100	118	100	125	150	175	200	225	250	300	≈ 2,09	
167.115.□.0	115	133	100	125	150	175	200	225	250	300	≈ 2,24	
167.125.□.0	125	143	100	125	150	175	200	225	250	300	≈ 2,35	
167.150.□.0	150	168	100	125	150	175	200	225	250	300	≈ 2,60	
167.175.□.0	175	193	100	125	150	175	200	225	250	300	≈ 2,86	
167.200.□.0	200	218	100	125	150	175	200	225	250	300	≈ 3,11	
167.225.□.0	225	243	100	125	150	175	200	225	250	300	≈ 3,37	
167.250.□.0	250	268	100	125	150	175	200	225	250	300	≈ 3,62	

Supplement Part No. with required radius. Example: 167.100.100.0

0 = standard color, other colors ► page 1.39 · Pitch = 58,8 mm/link - Links/m = 17

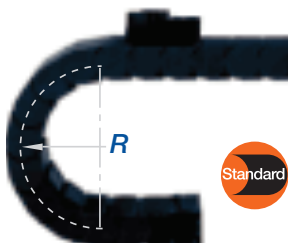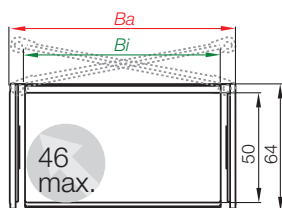

Part No. structure

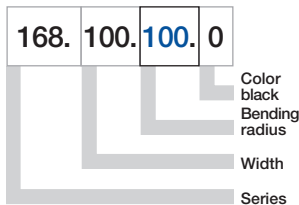

Series R168 - hinged, snap-open on both sides of the outer radius

Part No.	B_i [mm]	B_a [mm]	R [mm]	Bending radii								Weight [kg/m]
168.050.□.0	50	68	100	125	150	175	200	225	250	300	≈ 1,58	
168.075.□.0	75	93	100	125	150	175	200	225	250	300	≈ 1,84	
168.100.□.0	100	118	100	125	150	175	200	225	250	300	≈ 2,09	
168.115.□.0	115	133	100	125	150	175	200	225	250	300	≈ 2,24	
168.125.□.0	125	143	100	125	150	175	200	225	250	300	≈ 2,35	
168.150.□.0	150	168	100	125	150	175	200	225	250	300	≈ 2,60	
168.175.□.0	175	193	100	125	150	175	200	225	250	300	≈ 2,86	
168.200.□.0	200	218	100	125	150	175	200	225	250	300	≈ 3,11	
168.225.□.0	225	243	100	125	150	175	200	225	250	300	≈ 3,37	
168.250.□.0	250	268	100	125	150	175	200	225	250	300	≈ 3,62	

The sizes 125 / 225 / 250 are available upon request. Delivery time: approx. 8-10 weeks after receipt of order

Supplement Part No. with required radius. Example: 168.100.100.0

0 = standard color, other colors ► page 1.39 · Pitch = 58,8 mm/link - Links/m = 17

