
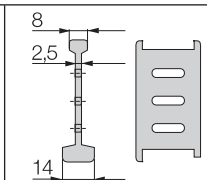


**Slotted separator for E-Chains®**

unassembled	<b>302</b>
assembled	<b>312</b>

**Slotted separator 302 (E-Chains® only)**

is used when vertical and horizontal separation is required. Due to its slot, it allows basic vertical/horizontal shelving arrangements.


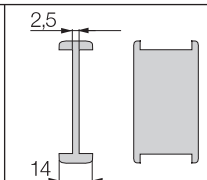



**Slotted separator for E-Tubes**

unassembled	<b>34501</b>
assembled	<b>34511</b>

**Slotted separator 34501 (E-Tubes only)**

is used when vertical and horizontal separation is required. Due to its slot, it allows basic vertical/horizontal shelving arrangements.


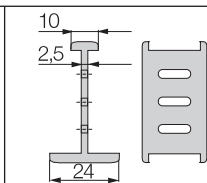



**Separator for E-Chains®**

unassembled	<b>301</b>
assembled	<b>311</b>

**Separator 301 (E-Chains® only)**

For a simple vertical subdivision on E-Chains®.


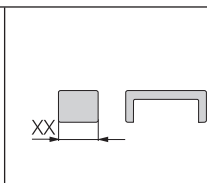



**Separator, wide foot\* for E-Chains®**

unassembled	<b>302.24</b>
assembled	<b>312.24</b>

**Separator, wide foot\* 302.24 (E-Chains® only)**

If a wide space between the separators has to be kept or separators have to be fixed in their position, e.g. for side-mounted applications. (\*for side-mounted applications)


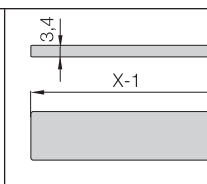



**Spacer\* E-Chains®**

unassembled	<b>305.XX</b>
assembled	<b>315.XX</b>

**Spacer\* 305.XX (E-Chains® only)**

Separators can be fixed in position (only mountable along the inner radius of the fixed crossbar), (\*for side-mounted applications). **XX = Breite Abstandhalter**, wählbar 8, 12 mm.

**Full-width shelf E-Chains®/E-Tubes**

unassembled	<b>320.X</b>
assembled	<b>321.X</b>

**Full-width shelf 320.X (E-Chains® and E-Tubes)**

This option makes sense in applications with many thin cables with similar diameters. For a consequent subdivision. Full-width shelves can be arranged at 3 different heights (in 12 mm increments).

**Full-width shelves**

Width X [mm]	unassembled	assembled	Width X [mm]	unassembled	assembled	Width X [mm]	unassembled	assembled
050	<b>320.050</b>	<b>321.050</b>	125	<b>320.125</b>	<b>321.125</b>	225	<b>320.225</b>	<b>321.225</b>
075	<b>320.075</b>	<b>321.075</b>	150	<b>320.150</b>	<b>321.150</b>	250	<b>320.250</b>	<b>321.250</b>
100	<b>320.100</b>	<b>321.100</b>	175	<b>320.175</b>	<b>321.175</b>			
115	<b>320.115</b>	<b>321.115</b>	200	<b>320.200</b>	<b>321.200</b>			

