


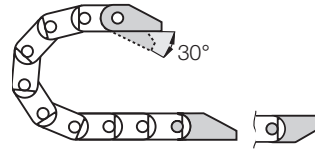


Polymer, one-piece

- One-piece mounting bracket
- Corrosion-resistant
- Available preassembled

Moving end with bore
(outer link) 040...1 (PZ)



 
040...2(PZ) Fixed end
with pin (inner link)



Possible installation conditions for assembled mounting brackets ▶ Order example "preassembled" below

040...1(PZ)
Moving end

040...2(PZ)
Fixed end

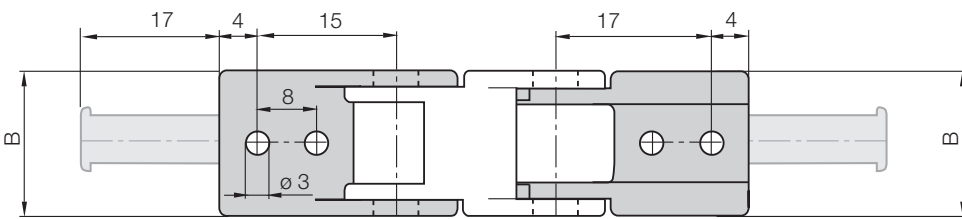


For E-Chain®	Part No. full set with tiewrap plate	Part No. full set without tiewrap plate	Number of teeth	Dim. B [mm]
E04.07. ▶	040.07. 12 PZ	040.07. 12	1	12

For the **preassembled** mode please add the index **A1 ... A4** e.g. 040.07. 12 PZ **A1**

Dimensions and order configurations

Part No. structure

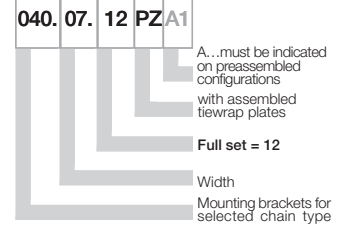

Full set, for both ends:

040. 07. 12 PZ +tiewrap plate

Single-part order:

040. 07. 1 PZ +tiewrap plate

Mounting bracket with bore

040. 07. 2 PZ +tiewrap plate

Mounting bracket with pin

Phone +49- (0) 22 03-96 49-800
Fax +49- (0) 22 03-96 49-222

 


Quicksnap - the complete, detachable mounting unit, available upon request



Quickfix - mounting bracket with dowel, available upon request

Additional Features



▶ page 3.5