





Polymer, one-piece

- One-piece mounting bracket
- Corrosion-resistant
- Available preassembled
- Inner and outer attachment possible
- Available with integrated strain relief tiwrap plates

Moving end with bore
(outer link) 060...1 (PZ)

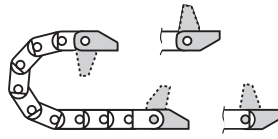


 060...2 (PZ) Fixed end
with pin (inner link)



Possible installation conditions for assembled mounting brackets ▶ Order example "preassembled" below

060...1 (PZ)
Moving end

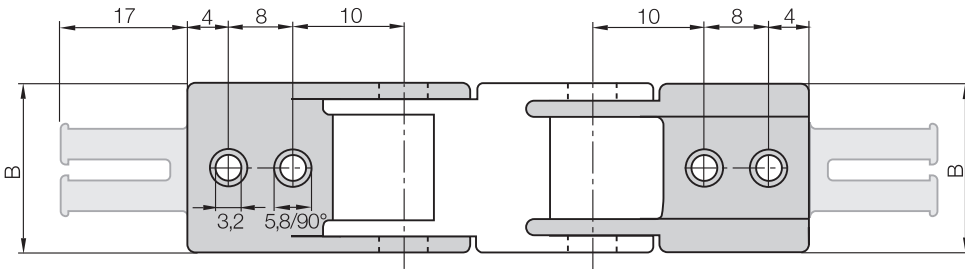


060...2 (PZ)
Fixed end

Dimensions and order configurations

Strain relief is possible on the moving end and/or the fixed end.

Part No. structure

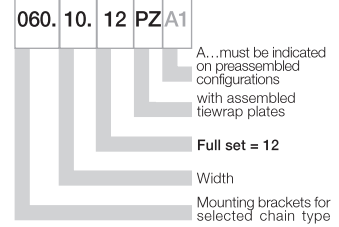

Full set, for both ends:

060. 10. 12 PZ +tiwrap plate

Single-part order:

060. 10. 1 PZ +tiwrap plate

Mounting bracket with bore

060. 10. 2 PZ +tiwrap plate

Mounting bracket with pin

For E-Chain®	Part No. full set with tiwrap plate	Part No. full set without tiwrap plate	Number of teeth	Dim. B [mm]
E06-Z06.10. ▶	060.10. 12 PZ	060.10. 12	1	16,5
E06-Z06.16. ▶	060.16. 12 PZ	060.16. 12	2	22,5
E06.20. ▶	060.20. 12 PZ	060.20. 12	2	27

For the preassembled mode please add the index A1 ... A4 e.g. 060.10. 12 PZ A1



Quicksnap - the complete, detachable mounting unit, available upon request



Quickfix - mounting bracket with dowel, available upon request

Additional Features

