


Series Z300 - split crossbar along the inner radius

Part No.	<i>Bi</i> [mm]	<i>Ba</i> [mm]	<i>R</i> [mm]	Bending radii	Weight [kg/m]
Z300.075.□.0	75	95	075	100 125 150 200 250 300	~1,60

Ba: pin dimension approx. 0,3 - 0,5 mm wider!

Supplement Part No. with required radius. Example: Z300.075.100.0

0 = standard color, other colors ► page 1.39 · Pitch = 67 mm/link - Links/m = 15

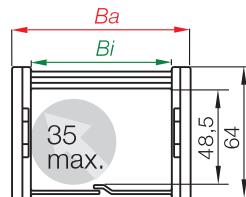


Series Z300 - split crossbar along the inner radius with 2-chamber system

Part No.	<i>Bi</i> [mm]	<i>Ba</i> [mm]	<i>R</i> [mm]	Bending radii	Weight [kg/m]
Z300.2/45.□.0	48/48	120	075	100 125 150 200 250 300	~1,78

Ba: pin dimension approx. 0,3 - 0,5 mm wider!

Supplement Part No. with required radius. Example: Z300.2/45.100.0

0 = standard color, other colors ► page 1.39 · Pitch = 67 mm/link - Links/m = 15

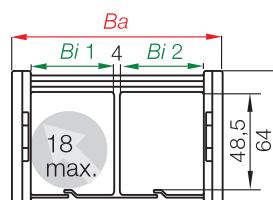



Series Z300 - split crossbar along the inner radius with 3-chamber system

Part No.	<i>Bi</i> [mm]	<i>Ba</i> [mm]	<i>R</i> [mm]	Bending radii	Weight [kg/m]
Z300.3/45.□.0	47/46/47	170	075	100 125 150 200 250 300	~1,92


Ba: pin dimension approx. 0,3 - 0,5 mm wider!

Supplement Part No. with required radius. Example: Z300.3/45.100.0

0 = standard color, other colors ► page 1.39 · Pitch = 67 mm/link - Links/m = 15

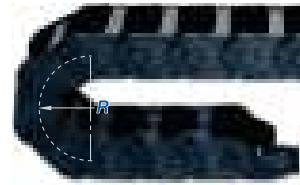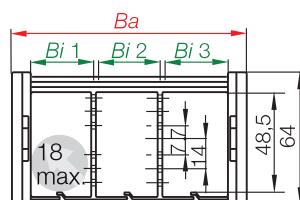



Part No. structure

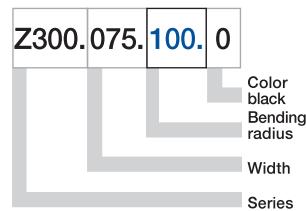

Easy Chain® | Series E300 · Z300 | Accessories | Interior Separation

Optional shelving for E300.3/45 · Z300.3/45

- Shelving enables subdivision of the inner space of the E-Chain® Series E300.3/45 and Z300.3/45. Shelves are only used when a horizontal subdivision is required.
- In standard configurations, shelves are installed in every other link.

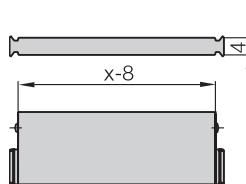
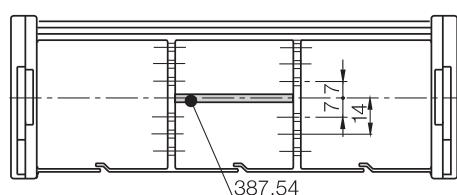


Shelves

unassembled	386.54
assembled	387.54

Easy Chain®
Inner height: 48,5 mm

Phone +49- (0) 22 03-96 49-800
Fax +49- (0) 22 03-96 49-222

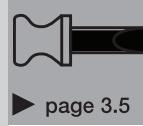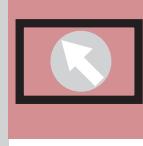

► page 3.5