 





Polymer, one-piece

- One-piece mounting bracket
- Corrosion-resistant
- Available preassembled

Moving end with bore
(outer link) 045...1

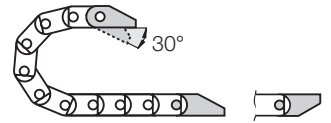

Possible installation conditions for assembled mounting brackets ► Order example "preassembled" below

045...2 E03...2Z Fixed end
with pin (inner link)



Dimensions and order configurations

045...1

Moving end


045...2

Fixed end

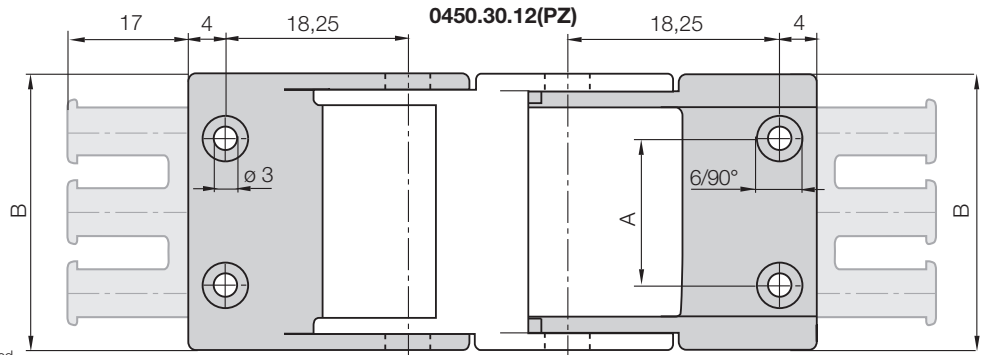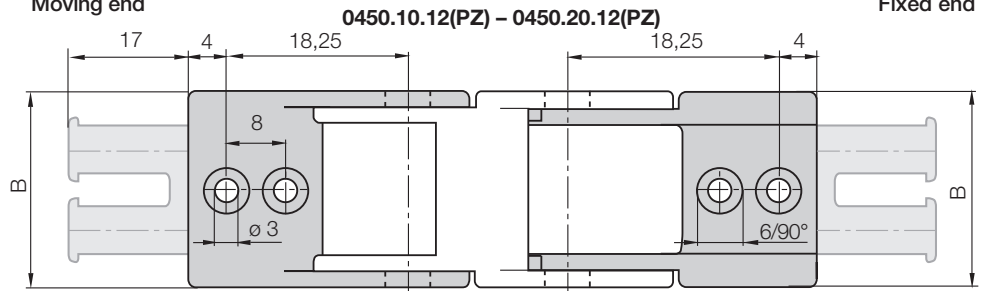

Part No. structure

0450. 10. 12 PZ A2

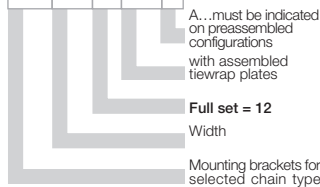

A...must be indicated on preassembled configurations with assembled tie-wrap plates
Full set = 12 Width
Mounting brackets for selected chain type

Full set, for both ends:

0450. 10. 12 PZ +tie-wrap plate

Single-part order:

0450. 10. 1 PZ +tie-wrap plate

Mounting bracket with bore

0450. 10. 2 PZ +tie-wrap plate

Mounting bracket with pin

For E-Chain®	Part No. full set with tie-wrap plate	Part No. full set without tie-wrap plate	Number of teeth	Dim. A [mm]	Dim. B [mm]
E045.10.	► 0450.10. 12 PZ	0450.10. 12	1	-	16
E/Z045.16.	► 0450.16. 12 PZ	0450.16. 12	2	-	22
E/Z045.2/7.	► 0450.16. 12 PZ	0450.16. 12	2	-	22
E045.2/9.	► 0450.20. 12 PZ	0450.20. 12	2	-	26
E045.3/9.	► 0450.30. 12 PZ	0450.30. 12	3	22	36

For the **preassembled** mode please add the index **A2** or **A4** e.g. 0450.20. 12 PZ **A2**

Mounting brackets with **tie-wrap plate** are available upon request. Time of delivery approx. 6-8 weeks after order. Mounting brackets without **tie-wrap plate** are available from stock.

Additional Features



Quicksnap - the complete, detachable mounting unit, available upon request



Quickfix - mounting bracket with dowel, available upon request