




**Option KMA\* - The Standard**

- Bolted connection outside of chain cross-section
- Split-on KMA mounting bracket
- Corrosion-resistant
- Available with or without strain relief tiwrap plates
- Universal mountable with attachment capability on all sides

\*KMA = Polymer Metal Mounting Bracket

Moving end with bore  
333...1PZ(B)

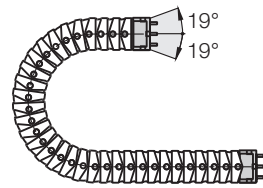


333...2PZ(B)

Fixed end with pin



These fastening variants result automatically on selection of dividable KMA mounting brackets

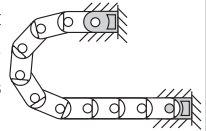


333...1PZ(B)

Moving end

333...2PZ(B)

Fixed end

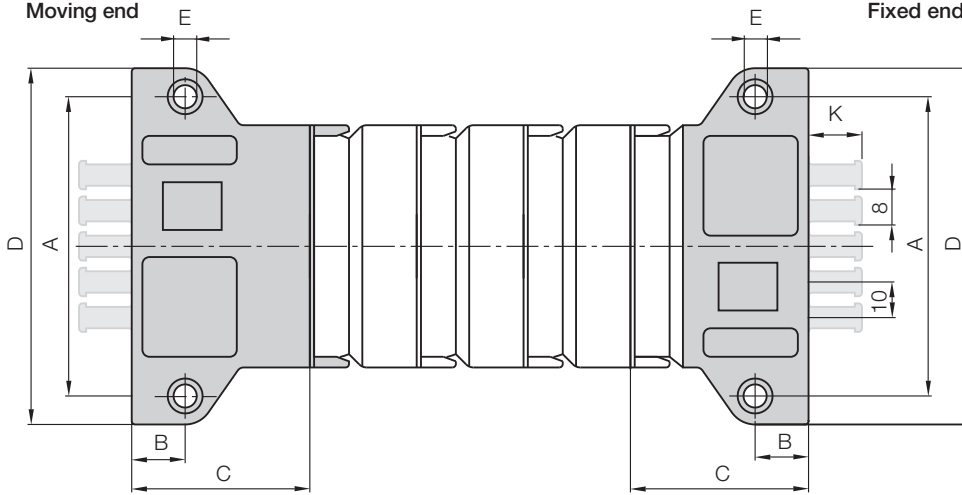

**Dimensions and order configurations**

For high loads, we recommend screwing the mounting brackets to the E-Chain®. Contact us if you have any questions.

Part No. structure

333.32.12.PZB.A

A...must be indicated on preassembled configurations  
With assembled strain relief tiwrap plates

Full set = 12

Mounting brackets for selected chain type

Full set, for both ends:

333.32.12.PZB +tiwrap plate

Single-part order:

333.32.1.PZB +tiwrap plate

Mounting bracket with bore

333.32.2.PZB +tiwrap plate

Mounting bracket with pin

| For E-Chain®        | Part No. Full set with tiwrap plate | Part No. Full set without tiwrap plate | Dim. A [mm] | Dim. B [mm] | Dim. C [mm] | Dim. D [mm] | Dim. E [mm] | Dim. K [mm] | Dim. of teeth |
|---------------------|-------------------------------------|--|-------------|-------------|-------------|-------------|-------------|-------------|---------------|
| E332.25.2 / E333.25 | -                                   | 333.25.12.PZ                           | 43          | 7           | 22          | 52          | 4,5         | -           | -             |
| E332.32.2 / E333.32 | 333.32.12.PZB                       | 333.32.12.PZ                           | 66          | 15          | 46          | 82          | 6,5         | 15          | 3             |
| E332.50.2 / E333.50 | 333.50.12.PZB                       | 333.50.12.PZ                           | 84          | 15          | 50          | 100         | 6,5         | 15          | 5             |
| E332.75.2 / E333.75 | 333.75.12.PZB                       | 333.75.12.PZ                           | 109         | 15          | 55          | 125         | 6,5         | 15          | 7             |

For the preassembled mode please add the index A, eg. 333.25.12.PZB.A

 
**Tiwrap plate as individual part**

**Special tiwrap plates for Easy Triflex® with KMA mounting brackets**

- Single-piece for installation inside switch cabinets or machine assembly
- Easy to assemble, no need for screws

| Part No. Tiwrap plate | Width [mm] | Number of teeth | For Series          |
|-----------------------|------------|-----------------|---------------------|
| 333.32.ZB             | 40         | 3               | E332.32.2 / E333.32 |
| 333.50.ZB             | 58         | 5               | E332.50.2 / E333.50 |
| 333.75.ZB             | 83         | 7               | E332.75.2 / E333.75 |

Phone +49- (0) 22 03-96 49-800  
Fax +49- (0) 22 03-96 49-222



► page 2.35