


## Interior separation

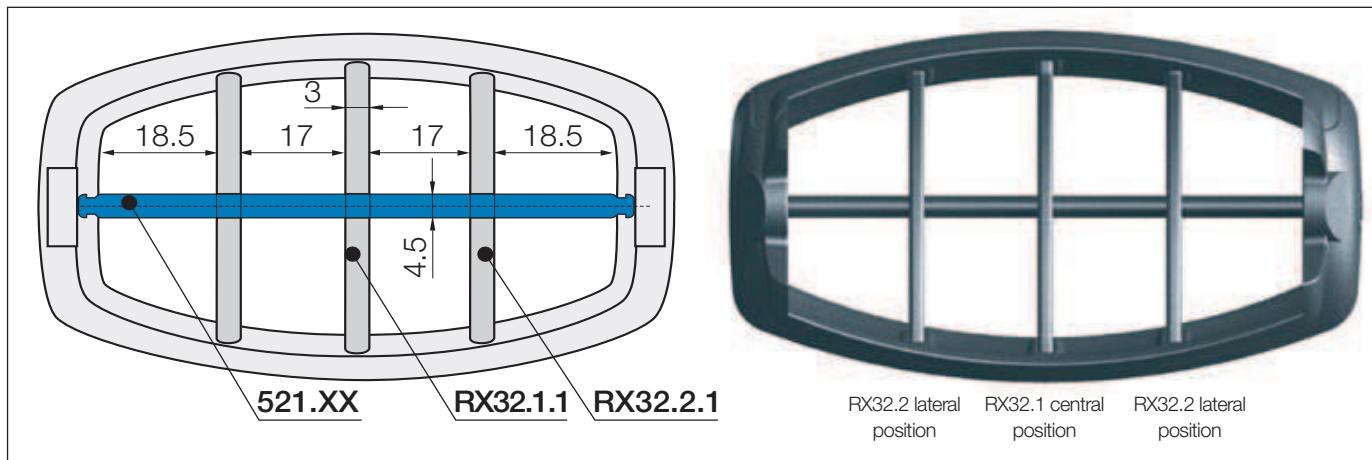

		<b>Slotted separator (central position)</b> unassembled <b>RX32.1</b> assembled <b>RX32.1.1</b>
		<b>Slotted separator (lateral position)</b> unassembled <b>RX32.2</b> assembled <b>RX32.2.1</b>
		<b>Shelf, lockable</b> unassembled <b>520.X</b> assembled <b>521.X</b>

**Vertical separation - slotted separators:****RX32.1** (central position)**RX32.2** (lateral position)

Vertical separation of the large interior space using cable-friendly, polymer separators. Due to their slots, basic vertical and horizontal shelving arrangements are possible. As standard igus® separators should be fitted every 2<sup>nd</sup> e-chain® link.

**Horizontal separation**

Full-width shelf locks securely into separators at both ends, giving a fixed width. Can be used as full-width or partial shelf.

**Shelves**

Width = X [mm]

**X** [mm] unassembled assembled024 **520.24** **521.24**044 **520.44** **521.44****X** [mm] unassembled assembled064 **520.64** **521.64**084 **520.84** **521.84**