





**Polymer, one-piece**

- One-piece mounting bracket
- Corrosion-resistant
- Available preassembled
- Inner and outer attachment possible
- Available with or without strain relief tiewrap plates

Moving end with bore (outer link) 11...1P(Z)

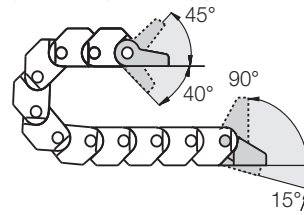

 
11...2P(Z) Fixed end with pin (inner link)



Possible installation conditions for assembled mounting brackets ► Order example "preassembled" below

11...1P(Z)  
Moving end


11...2P(Z)  
Fixed end

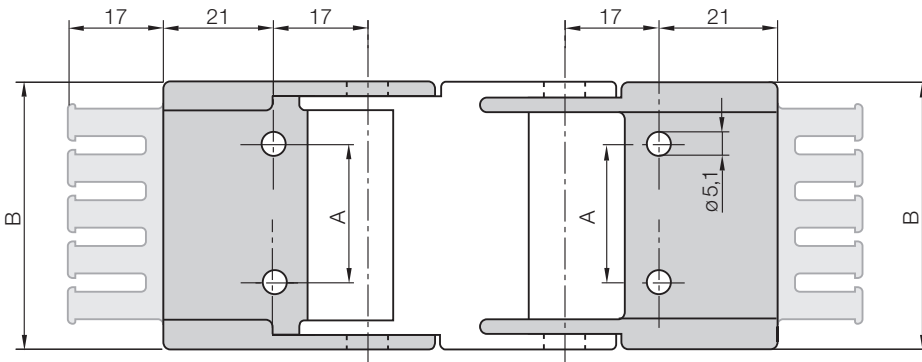

**Dimensions and order configurations**

Strain relief is possible on the moving end and/or the fixed end.

**Part No. structure**

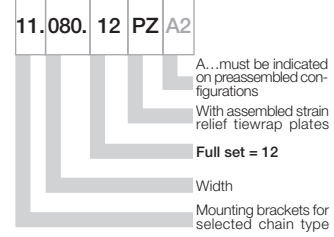

**Full set, for both ends:**

11.080.12PZ +tiewrap plate

**Single-part order:**

11.080.1PZ +tiewrap plate

Mounting bracket with bore

11.080.2PZ +tiewrap plate

Mounting bracket with pin

For E-chain®	Part No. full set with tiewrap plate	Part No. full set without tiewrap plate	Dim. A [mm]	Dim. B [mm]
11.080. ►	11.080.12PZ	11.080.12P	65	93

For the preassembled mode please add the index A2 e.g. 11.080.12PZ A2

Phone +49- (0) 22 03-96 49-800  
Fax +49- (0) 22 03-96 49-222

