


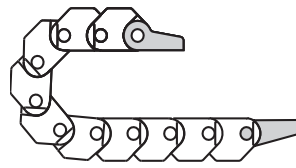


Polymer, one-piece

- One-piece mounting bracket
- Corrosion-resistant
- Available preassembled
- Inner and outer attachment possible
- Available with or without strain relief tiwrap plates

Moving end with bore
(outer link) 10...1P(Z)



 
10...2P(Z) Fixed end
with pin (inner link)



Possible installation condition for assembled mounting brackets ▶ Order example "preassembled" below

10...1P(Z)
Moving end


10...2P(Z)
Fixed end

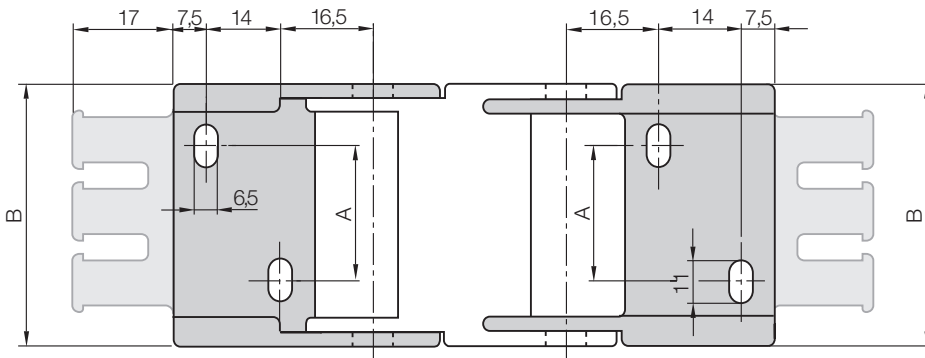

Dimensions and order configurations

Strain relief is possible on the moving end and/or the fixed end.

Part No. structure

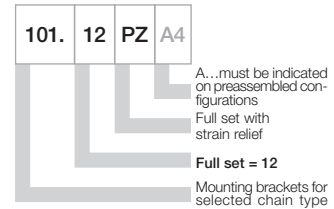

Full set, for both ends:

101.12PZ +tiwrap plate

Single-part order:

101.1PZ +tiwrap plate

Mounting bracket with bore

101.2PZ +tiwrap plate

Mounting bracket with pin


For E-Chain®	Part No. full set with tiwrap plate	Part No. full set without tiwrap plate	Dim. A [mm]	Dim. B [mm]
11.1. ▶	101.12PZ	101.12P	-	26
11.2. ▶	102.12PZ	102.12P	10	36

For the preassembled mode please add the index A4 e.g. 101.12PZA4

Also available:

Option: Steel, one-piece

- One-piece mounting bracket
- Available pre-assembled

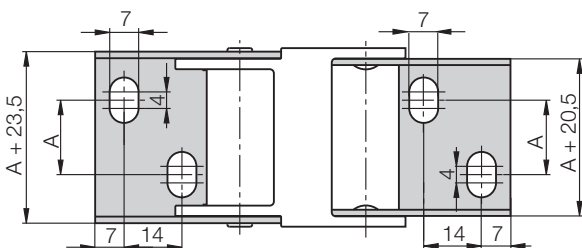


For E-Chain®	Part No. one-piece	Part No. set two-piece	Dim. A* [mm]	Dim. B* [mm]
11.1 ▶	101.12	100.12	-	3
11.2 ▶	102.12	100.12	10	13


*A may be equal to B owing to slot

Option: Steel, two-piece

- 1 set, suitable for all widths
- Inner and outer attachment possible

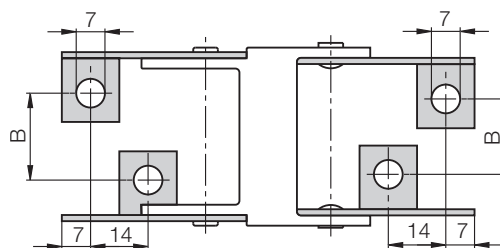

 Phone +49- (0) 22 03-96 49-800
Fax +49- (0) 22 03-96 49-222



▶ page 5.47