
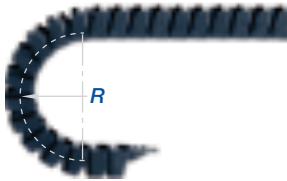


igus® E-ChainSystems®

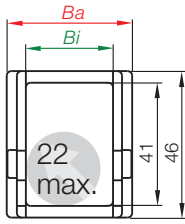


Series 11.1/11.2 E-Chain® - non snap-open

Part No.	Bi [mm]	Ba [mm]	R [mm]	Bending radii	Weight [kg/m]
11.1. <input type="text"/> .0	15	25,5	<input type="text" value="040"/>	<input type="text" value="063"/> <input type="text" value="075"/> <input type="text" value="100"/>	≈ 0,50
11.2. <input type="text"/> .0	25	35,5	<input type="text" value="040"/>	<input type="text" value="063"/> <input type="text" value="075"/> <input type="text" value="100"/>	≈ 0,53

Supplement Part No. with required radius. Example: 11.2. .0

0 = standard color, other colors ► page 1.39 · Pitch = 30,5 mm/link - Links/m = 33

Part No. structure

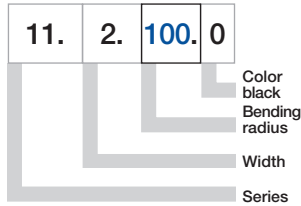

Phone +49- (0) 22 03-96 49-800
Fax +49- (0) 22 03-96 49-222

igus® GmbH
51147 Cologne

Internet: www.igus.eu
E-mail: info@igus.de