
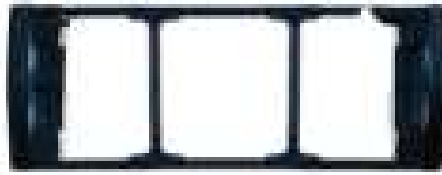


Option 1: Vertical Separators

Vertical Separators are used if a vertical subdivision of the E-Chain® interior is required -


By standard Vertical Separators are assembled every other E-Chain® link

- Standard subdivision with Vertical Separator, slotted 172B (for B17.1 to B17.4) or, Vertical Separator, slotted 174B (for B17.5 to B17.7) for combinations with Full-Width Shelf 111.X

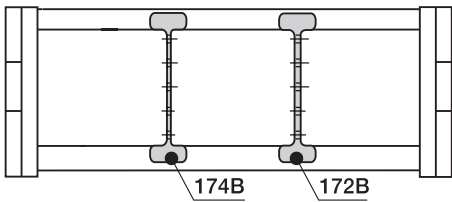


Vert. Separator, slotted for B17.1 to B17.4

unassembled	171B
assembled	172B

 

Vert. Separator, slotted for B17.5 to B17.7

unassembled	173B
assembled	174B


 


E2 mini
Inner height: 32 mm

Option 2: Full-Width Shelves


For applications involving many thin cables with similar or identical diameters

- Side Plate 156 can be combined with Vertical Separator, slotted 172B (for B17.1 to B17.4) or Vertical Separator, slotted 174B (for B17.5 to B17.7) and Full-Width Shelf 111.X

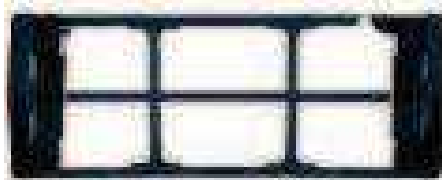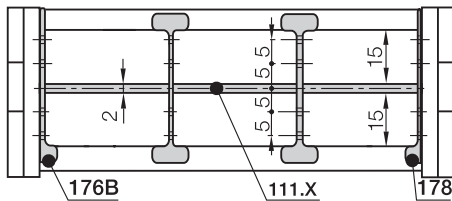


Side Plate for B17.1 to B17.4

unassembled	175B
assembled	176B

 

Side Plate for B17.5 to B17.7

unassembled	177
assembled	178

 

Phone +49- (0) 22 03-96 49-800
Fax +49- (0) 22 03-96 49-222

Width X [mm]	Part No. unassembled	Part No. assembled
015	110.15	111.15
025	110.25	111.25
038	110.38	111.38
050	110.50	111.50

Width X [mm]	Part No. unassembled	Part No. assembled
063	110.63	111.63
080	110.80	111.80
100	110.100	111.100

Full-Width Shelf

