

Steel pivoting | Recommended for unsupported, gliding and vertical standing applications


Steel locking | Recommended for unsupported, gliding, vertical hanging and vertical standing applications

Part No. full set	Description
steel pivoting	Mounting bracket
E4.16210. 1 .34.VS. E	Full set (both ends), ending with outer side link, screwed - standard
E4.16210. 2 .34.VS. E	Full set (both ends) - beginning with outer side link (moving end) - ending with inner side link (fixed end), screwed - standard

Stainless steel version available. Please add the index **.E!** (Material: stainless steel 1.4301)

Part No. full set	Description
steel locking	Mounting bracket
E4.16210. 1 .12.VS. E	Full set (both ends), ending with outer side link, screwed - standard
E4.16210. 2 .12.VS. E	Full set (both ends) - beginning with outer side link (moving end) - ending with inner side link (fixed end), screwed - standard

Stainless steel version available. Please add the index **.E!** (Material: stainless steel 1.4301)

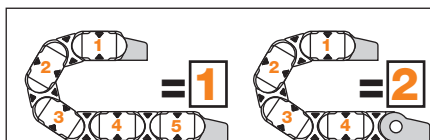

Note: depending on the chain length, the e-chain® may end with **1** either an outer or an **2** inner side link. For the best appearance, make sure the e-chain® ends with **1** outer side links whenever possible. (with odd number of links)



Strain relief e.g. clamps, tiwrap plates, nuggets and plug-in clips are available from stock. The complete chainfix range with ordering options ► From page 1098