


Part No. structure

E4.21.120.100.0



Series E4.21 - E-Chain® with crossbars every link

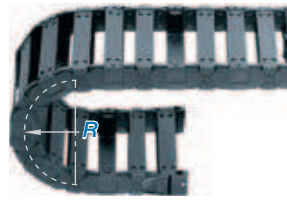

- Robust solution with crossbars every link
- Can be opened from two sides
- Removable crossbars
- Separator for locking crossbar (fixable) Standard



Part No.	<i>Bi</i> [mm]	<i>Ba</i> [mm]	Weight [kg/m]
E4.21.030.□.0	30	44	≈ 0,60
E4.21.040.□.0	40	54	≈ 0,64
E4.21.050.□.0	50	64	≈ 0,67
E4.21.060.□.0	60	74	≈ 0,71
E4.21.070.□.0	70	84	≈ 0,74
E4.21.080.□.0	80	94	≈ 0,78
E4.21.090.□.0	90	104	≈ 0,82
E4.21.100.□.0	100	114	≈ 0,85
E4.21.110.□.0	110	124	≈ 0,89
E4.21.120.□.0	120	134	≈ 0,92

Available bending radii

R [mm] 038 048 063 075 100 150 200

Supplement Part No. with required radius. Example: E4.21.120.□100□.0

0 = standard color, other colors ▶ page 5.65 · Pitch: 30,5 mm/link - Links/m = 33

Part No. E-Chain® links, single parts

