

Part No.	<i>Bi</i> [mm]	<i>Ba</i> [mm]	E4.28 [kg/m]	R4.28 [kg/m]
E4.28.040..... <input type="text"/> .0	40	60	≈ 1,06	-
E4.28/R4.28.050..... <input type="text"/> .0	50	70	≈ 1,11	≈ 2,20
E4.28.062..... <input type="text"/> .0	62	82	≈ 1,17	-
E4.28.070..... <input type="text"/> .0	70	90	≈ 1,20	-
E4.28/R4.28.075..... <input type="text"/> .0	75	95	≈ 1,23	-
E4.28.087..... <input type="text"/> .0	87	107	≈ 1,28	-
E4.28/R4.28.100..... <input type="text"/> .0	100	120	≈ 1,37	≈ 2,54
E4.28/R4.28.125..... <input type="text"/> .0	125	145	≈ 1,51	≈ 2,78
E4.28/R4.28.150..... <input type="text"/> .0	150	170	≈ 1,61	≈ 3,02
E4.28/R4.28.175..... <input type="text"/> .0	175	195	≈ 1,71	≈ 3,26
E4.28/R4.28.200..... <input type="text"/> .0	200	220	≈ 1,84	≈ 3,50
E4.28/R4.28.225..... <input type="text"/> .0	225	245	≈ 1,99	≈ 3,82
E4.28/R4.28.250..... <input type="text"/> .0	250	270	≈ 2,14	≈ 3,98
E4.28.275..... <input type="text"/> .0	275	295	≈ 2,27	-
E4.28/R4.28.300..... <input type="text"/> .0	300	320	≈ 2,39	≈ 4,46


*not available for R4.28

Available bending radii


R [mm] * *

Supplement Part No. with required radius. Example: E4.28.300..0

0 = standard color, other colors ▶ page 5.65 · Pitch: 46 mm/link - Links/m = 22

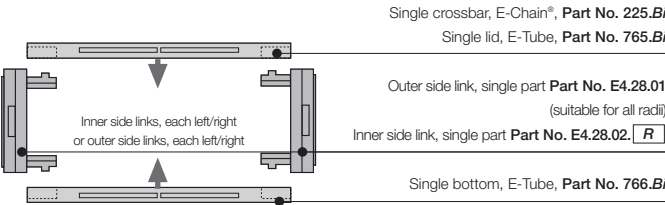

Part No. E-Chain® links, single parts

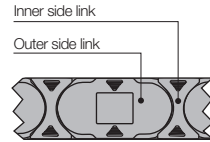

Hot Chips up to 850°C

E-Tubes that repel hot chips, up to 850°C - Some applications, depending on amount and size of the chips, left burn- and melt marks. That is no longer the case with the igus® "igumid HT" material.

Further Information: www.igus.de/en/HT

System E4.1
Inner height: 28 mm

Phone +49- (0) 22 03-96 49-800
Fax +49- (0) 22 03-96 49-222



▶ 5.241