


E4.1 | e-tubes R4.80 | Accessories


KMA mounting brackets | Attachment from any side | Pivoting | Locking

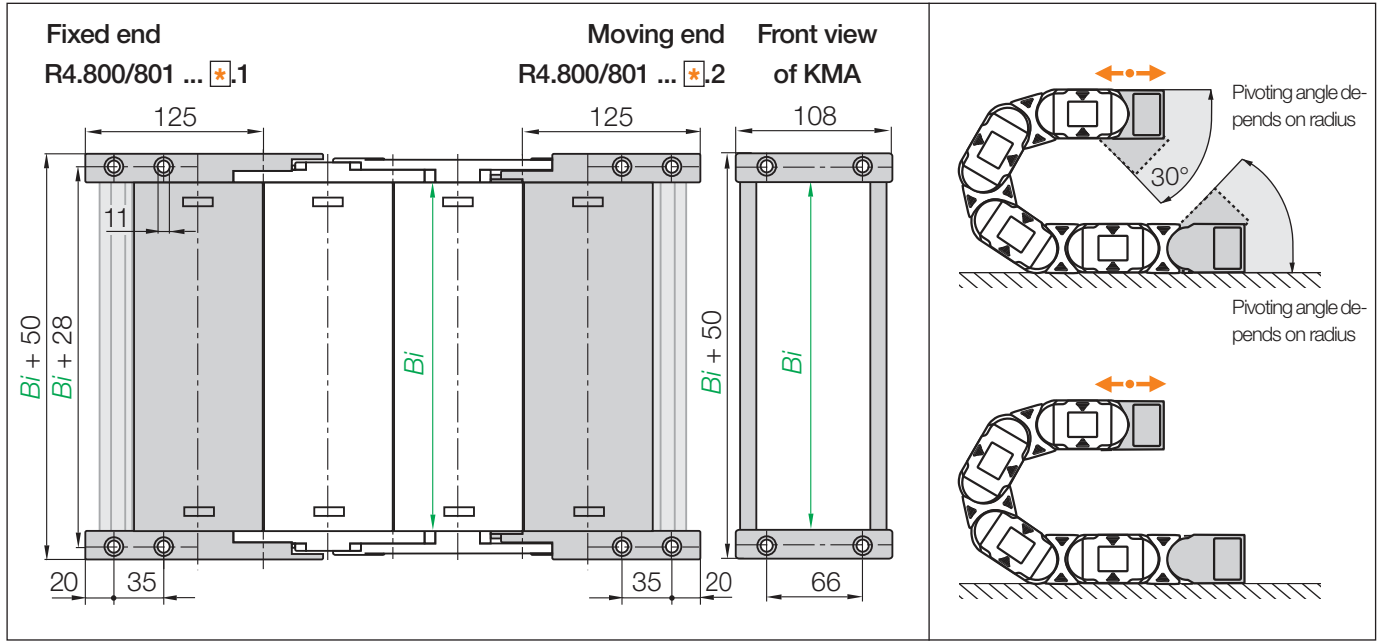

KMA pivoting | Recommended for unsupported and gliding applications
KMA locking | Recommended for vertical hanging and standing applications

Width index	Part No. full set KMA pivoting	Part No. full set KMA locking	Bi [mm]	Width index	Part No. full set KMA pivoting	Part No. full set KMA locking	Bi [mm]
10.	R4.800.10 .*.12.C	R4.801.10 .*.12.C	100	30.	R4.800.30 .*.12.C	R4.801.30 .*.12.C	300
15.	R4.800.15 .*.12.C	R4.801.15 .*.12.C	150	35.	R4.800.35 .*.12.C	R4.801.35 .*.12.C	350
20.	R4.800.20 .*.12.C	R4.801.20 .*.12.C	200	40.	R4.800.40 .*.12.C	R4.801.40 .*.12.C	400
25.	R4.800.25 .*.12.C	R4.801.25 .*.12.C	250	46.	R4.800.46 .*.12.C	R4.801.46 .*.12.C	462

(KMA = polymer metal mounting bracket) For the C-profile option please add index **C**

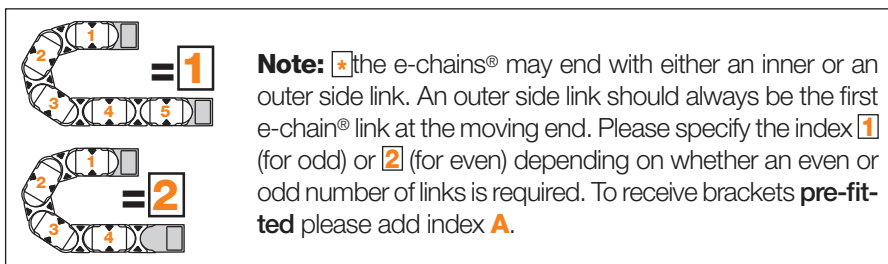

E4.800.30.2.12.C.A Order example

- A** ... To indicate option with brackets pre-fitted
- C-profile option
- Full set
- Even numbers of links
- Width index
- e-chain® series



Strain relief e.g. clamps, tiwrap plates, nuggets and plug-in clips are available from stock. The complete chainfix range with ordering options ► From page 1098