


KMA mounting brackets | Attachment from any side | Pivoting | Locking


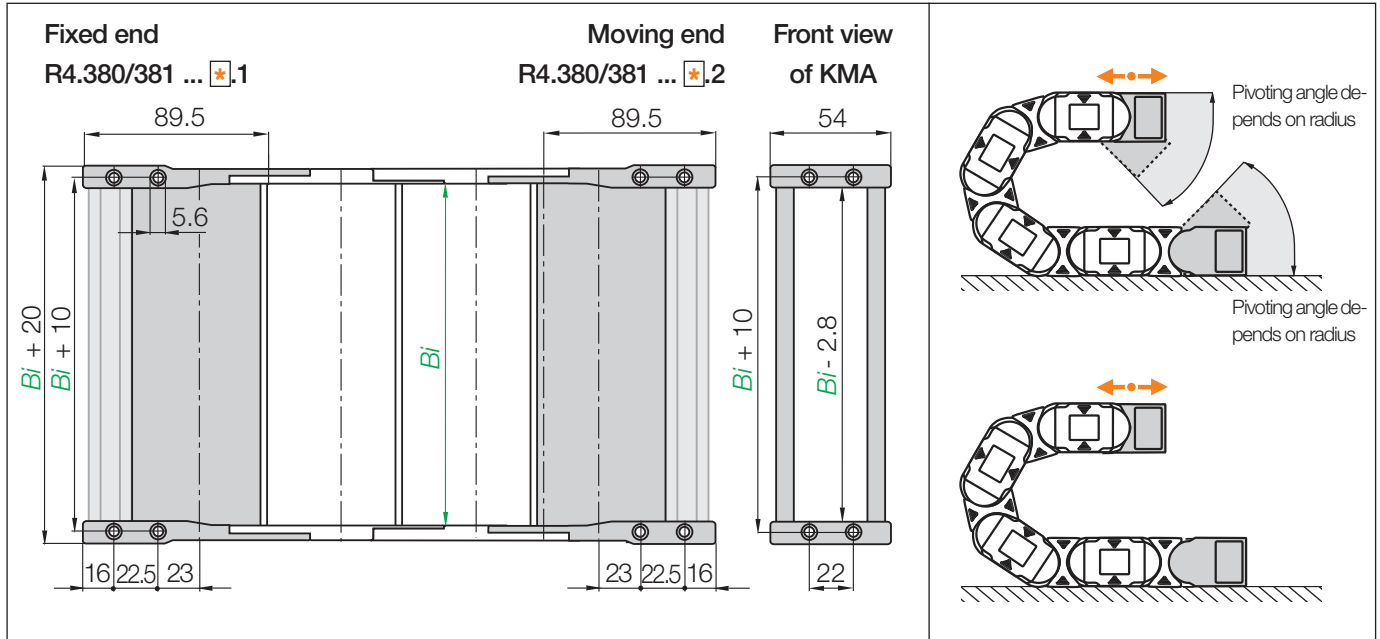


KMA pivoting | Recommended for unsupported and gliding applications
KMA locking | Recommended for vertical hanging and standing applications

Width index	Part No. full set KMA pivoting	Part No. full set KMA locking	Bi [mm]	Width index	Part No. full set KMA pivoting	Part No. full set KMA locking	Bi [mm]
050.	R4.380.050.*.12.C	R4.381.050.*.12.C	050	175.	R4.380.175.*.12.C*	R4.381.175.*.12.C*	175
075.	R4.380.075.*.12.C	R4.381.075.*.12.C	075	200.	R4.380.200.*.12.C	R4.381.200.*.12.C	200
100.	R4.380.100.*.12.C	R4.381.100.*.12.C	100	250.	R4.380.250.*.12.C	R4.381.250.*.12.C	250
125.	R4.380.125.*.12.C	R4.381.125.*.12.C	125	300.	R4.380.300.*.12.C*	R4.381.300.*.12.C*	300
150.	R4.380.150.*.12.C	R4.381.150.*.12.C	150				

(KMA = polymer metal mounting bracket) For the C-profile option please add index **C**

*Width available upon request. Please consult igus® for delivery time.

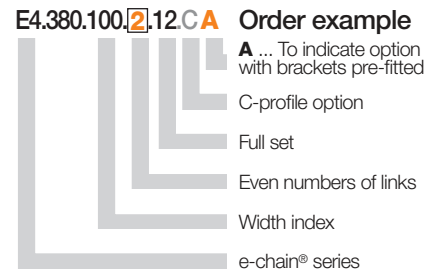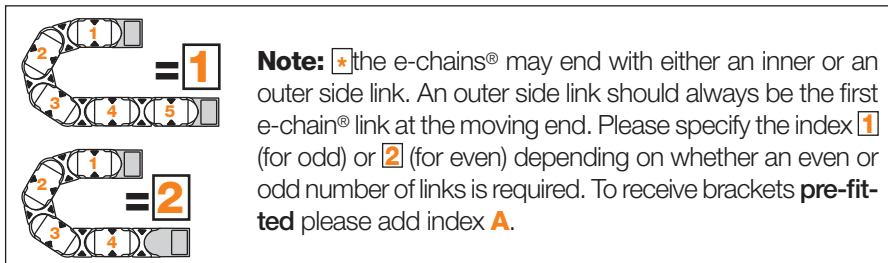

Strain relief e.g. clamps, tiwrap plates, nuggets and plug-in clips are available from stock. The complete chainfix range with ordering options ► From page 1098