





### Option steel - pivoting

- For pivoting connections
- One part (two-piece) for all chain widths
- Electrically conductive

Moving end  
28280.1

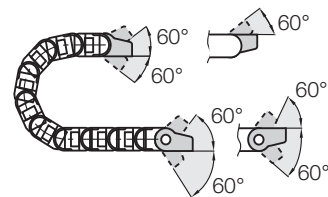

 Fixed end  
28280.2



Possible installation conditions -


Further installation angles ► installation sketch

Phone +49- (0) 22 03-96 49-800  
Fax +49- (0) 22 03-96 49-222

igus® GmbH  
51147 Cologne

Internet: [www.igus.eu](http://www.igus.eu)  
E-mail: [info@igus.de](mailto:info@igus.de)

Moving end 28280.1 Fixed end 28280.2

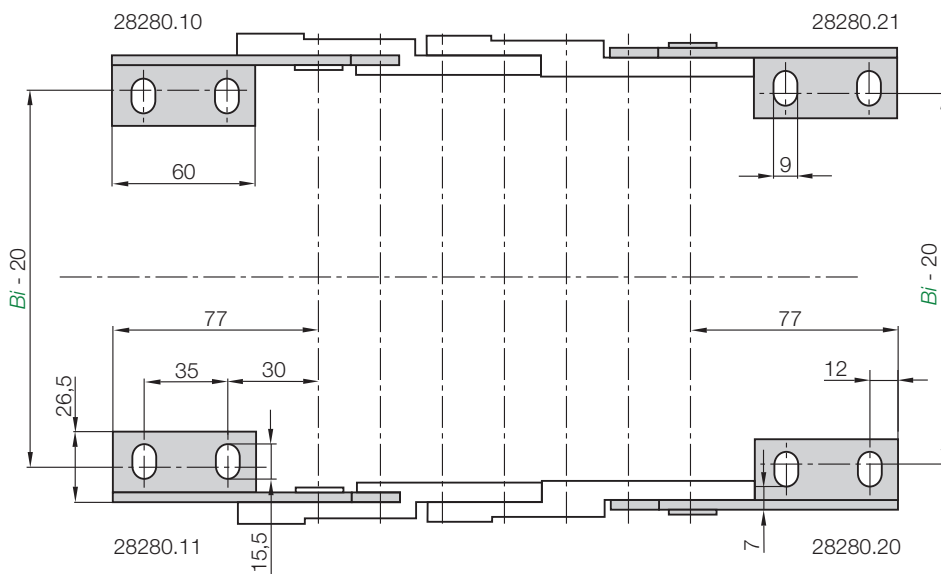

For E-Chain®	Part No. full set	Bi [mm]	For E-Chain®	Part No. full set	Bi [mm]
2828-2928-7728.05 ►	28280.12	50	2828-2928.23 ►	28280.12	225
2828-2928.06 ►	28280.12	68	2828-2928.237 ►	28280.12	237
2828-2928-7728.07 ►	28280.12	75	2828-2928-7728.25 ►	28280.12	250
2828-2928.087 ►	28280.12	87	2828-2928.262 ►	28280.12	262
2828-2928-7728.10 ►	28280.12	100	2828-2928.28 ►	28280.12	275
2828-2928-7728.11 ►	28280.12	108	2828-2928.29 ►	28280.12	287
2828-2928.112 ►	28280.12	112	2828-2928-7728.30 ►	28280.12	300
2828-2928-7728.12 ►	28280.12	125	2828-2928.312 ►	28280.12	312
2828-2928.137 ►	28280.12	137	2828-2928.325 ►	28280.12	325
2828-2928-7728.15 ►	28280.12	150	2828-2928.337 ►	28280.12	337
2828-2928.162 ►	28280.12	162	2828-2928.350 ►	28280.12	350
2828-2928-7728.17 ►	28280.12	168	2828-2928.362 ►	28280.12	362
2828-2928.18 ►	28280.12	175	2828-2928.375 ►	28280.12	375
2828-2928.187 ►	28280.12	187	2828-2928.387 ►	28280.12	387
2828-2928-7728.20 ►	28280.12	200	2828-2928.400 ►	28280.12	400
2828-2928.212 ►	28280.12	212			

28280.12 Full set, 4 parts  
2 with pin / 2 with bore

**Single-part order:**

28280.1 Mounting bracket  
moving end, 1 part left / right  
28280.2 Mounting bracket  
fixed end, 1 part left / right

Other strain relief elements  
► chapter 10