


The Standard - Option KMA* - pivoting

- Recommended for unsupported and gliding applications
- Confined installation conditions
- Option - integrated C-profile strain relief device with Chainfix clip or strain relief tiwrap plates
- Corrosion resistant
- Universal mountable with attachment capability on all sides

*KMA = Polymer Metal Mounting Bracket

 

Moving end
38380/78380...1

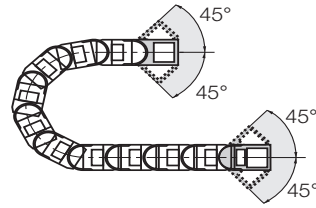

Fixed end
38380/78380...2



The attachment variants arising automatically by the choice of the KMA mounting bracket

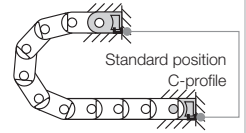


Option KMA - locking

- Recommended for vertical hanging / standing applications

Additionally:

- Universal mountable
- C-profile option
- Corrosion resistant
- Locked connections
- At very high acceleration


Moving end
39380/79380...1

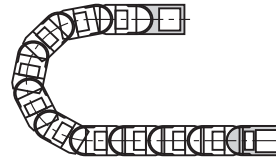

Fixed end
39380/79380...2




The attachment variants arising automatically by the choice of the KMA mounting bracket

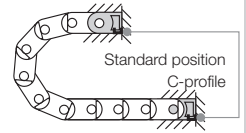

Fixed end
38380/78380...2 (pivoting)
39380/79380...2 (locking)

Moving end
(pivoting) 38380/78380...1
(locking) 39380/79380...1

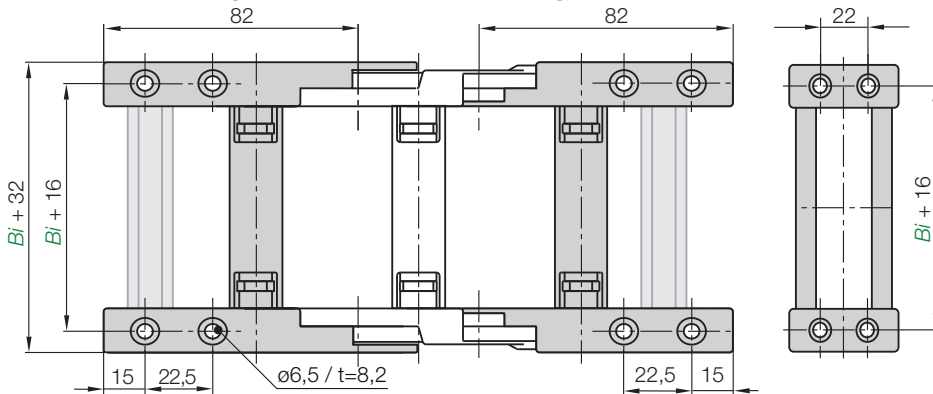

Dimensions and order configurations

Part No. structure (pivoting)

38380.	05.	12.	C
78380.			

Optional with C-profile
Full set
Width
38380 = E-Chain®
78380 = E-Tube

Part No. structure (locking)

39380.	05.	12.	C
79380.			

Optional with C-profile
Full set
Width
38380 = E-Chain®
77380 = E-Tube

Width index	Part No. full set pivoting	Part No. full set locking	C-profile option [mm]	Bi	Width index	Part No. full set pivoting	Part No. full set locking	C-profile option [mm]	Bi
.05.	38380/78380	39380/79380	.05.12.C	50	.23.	38380	39380	.23.12.C	225
.06.	38380	39380	.06.12.C	68	.237.	38380	39380	.237.12.C	237
.07.	38380/78380	39380/79380	.07.12.C	75	.25.	38380/78380	39380/79380	.25.12.C	250
.087.	38380	39380	.087.12.C	87	.262.	38380	39380	.262.12.C	262
.10.	38380/78380	39380/79380	.10.12.C	100	.28.	38380	39380	.28.12.C	275
.11.	38380/78380	39380/79380	.11.12.C	108	.29.	38380	39380	.29.12.C	287
.112.	38380	39380	.112.12.C	112	.30.	38380/78380	39380/79380	.30.12.C	300
.12.	38380/78380	39380/79380	.12.12.C	125	.312.	38380	39380	.312.12.C	312
.137.	38380	39380	.137.12.C	137	.325.	38380	39380	.325.12.C	325
.15.	38380/78380	39380/79380	.15.12.C	150	.337.	38380	39380	.337.12.C	337
.162.	38380	39380	.162.12.C	162	.350.	38380	39380	.350.12.C	350
.17.	38380/78380	39380/79380	.17.12.C	168	.362.	38380	39380	.362.12.C	362
.18.	38380	39380	.18.12.C	175	.375.	38380	39380	.375.12.C	375
.187.	38380	39380	.187.12.C	187	.387.	38380	39380	.387.12.C	387
.20.	38380/78380	39380/79380	.20.12.C	200	.400.	38380	39380	.400.12.C	400
.212.	38380	39380	.212.12.C	212					

Full set, for both ends:

38380.05.12

Single-part order:

38380.05.1

Mounting bracket moving end

38380.05.2

Mounting bracket fixed end