


Pendellager-Gleitdurchführungen

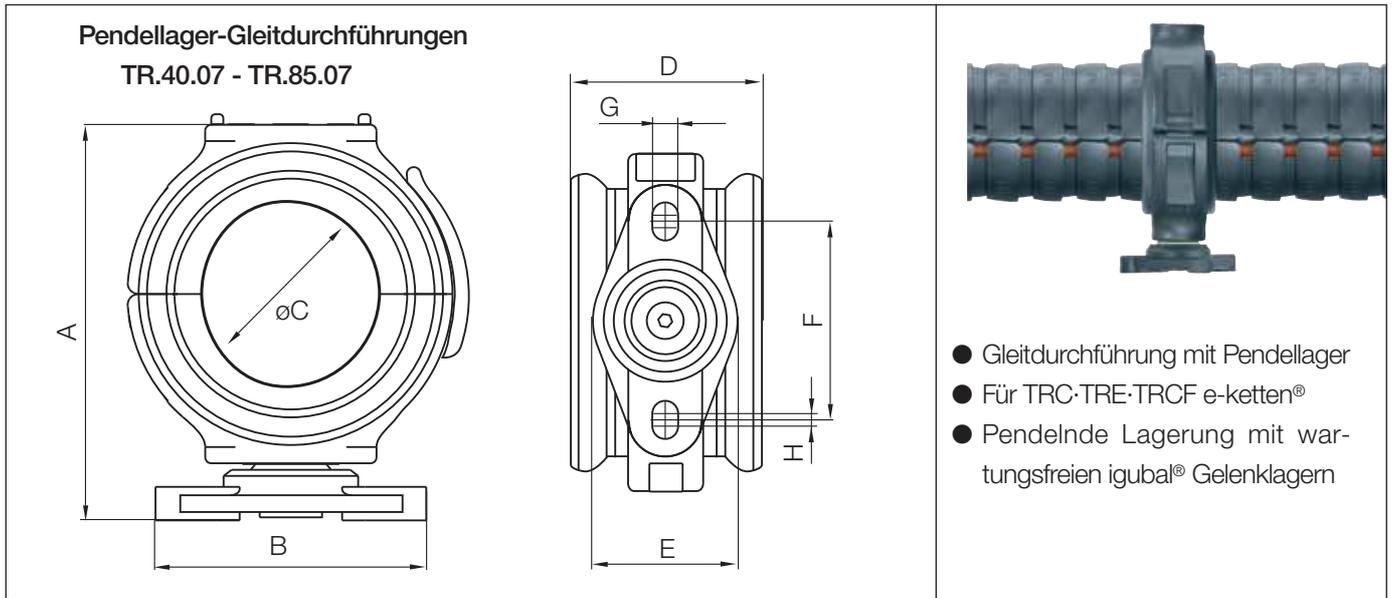

Pendellager-Gleitdurchführungen | Für TRC·TRE·TRCF

TR.40.07 -
TR.85.07

Ø	Art. Nr.	A	B	C	D	E	F	G
Index	mit Pendellager	[mm]						
30.	▶ -	-	-	-	-	-	-	-
40.	▶ TR.40.07	108	89	46	32	47	65	8,4
50.	▶ TR.50.07	119	89	58	67	47	65	8,4
60.	▶ TR.60.07	156	118	70	50	65	87,5	10,5
65.	▶ TR.65.07	156	118	75	75	65	87,5	10,5
70.	▶ TR.70.07	183	118	86	70	65	87,5	10,5
85.	▶ TR.85.07	183	118	100	84	65	87,5	10,5
85. (R 240)	▶ TR.85.07 ⁴⁾	183	118	100	84	65	87,5	10,5
100.	▶ -	-	-	-	-	-	-	-
125.	▶ -	-	-	-	-	-	-	-

4) Nur für Sondergröße TRCF.85.240.0 mit 240er Biegeradius