
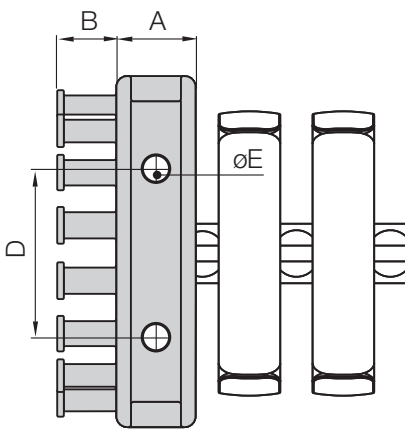
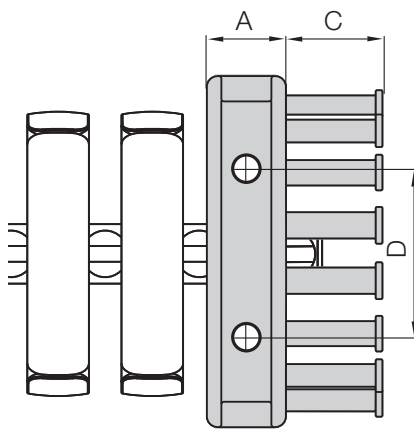


Short strain relief TL.30.01.Z1 - TL.100.01.Z1	Long strain relief TL.40.01.Z2 - TL.100.01.Z2	
		<ul style="list-style-type: none"> ● Recommended for TRL/TRLF, also compatible with TRC/TRE/TRCF ● Light fixation onto the machine/robot with strain relief ● Options with long or short strain relief

Standard Light mounting brackets | With strain relief



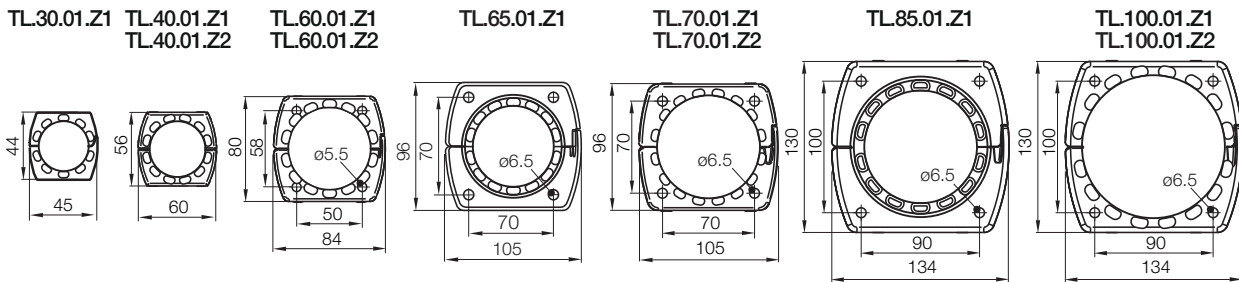
TL.30.01.Z1 - TL.100.01.Z1



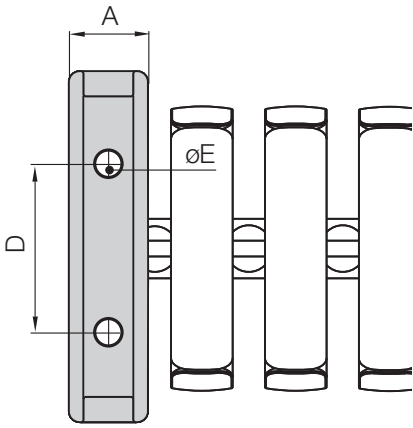
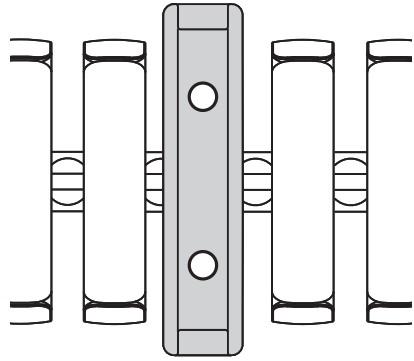

TL.40.01.Z2 - TL.100.01.Z2

Ø Index	Part No. with short strain relief	Part No. with long strain relief	A [mm]	B [mm]	C [mm]	D [mm]	E [mm]
30.	▶ TL.30.01.Z1	–	13	12.5	–	24	4.5
40.	▶ TL.40.01.Z1 ¹⁾	TL.40.01.Z2	14	12.5	20	36	5.8
50.	▶ Alternative: standard mounting bracket		–	–	–	–	–
60.	▶ TL.60.01.Z1 ¹⁾	TL.60.01.Z2	20	17	27	48	5.8
65.	▶ TL.65.01.Z1 ¹⁾	–	27	13.5	–	64	6.5
70.	▶ TL.70.01.Z1 ¹⁾	TL.70.01.Z2	27	17.5	27.5	64	6.5
85.	▶ TL.85.01.Z1	–	30	26.5	–	64	6.5
85. (R 240)	▶ Alternative: standard mounting bracket		–	–	–	–	–
100.	▶ TL.100.01.Z1 ¹⁾	TL.100.01.Z2	30	22.5	42.5	64	6.5
125.	▶ Alternative: standard mounting bracket		–	–	–	–	–

1) For moving end (ball) suitable only for series TRL/TRLF



Light mounting brackets | Without strain relief

<p>Without strain relief TL.30.01.Z0 - TL.100.01.Z0</p> 	<p>Intermediate bracket TL.30.01.Z0 - TL.100.01.Z0</p> 	 <ul style="list-style-type: none"> ● Recommended for TRL/TRLF, also compatible with TRC/TRE/TRCF ● Light fixation onto the machine/robot without strain relief ● Can also serve as intermediate bracket
-----------------------------------------------------------------------------------------------------------------------------------------------	-----------------------------------------------------------------------------------------------------------------------------------------------	------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------

Light mounting brackets | Without strain relief



TL.30.01.Z0 - TL.100.01.Z0

Ø Index	Part No. without strain relief or as intermediate bracket	A [mm]	B [mm]	C [mm]	D [mm]	E [mm]
30.	▶ TL.30.01.Z0	13	-	-	24	4.5
40.	▶ TL.40.01.Z0	14	-	-	36	5.8
50.	▶ Alternative: standard mounting bracket	-	-	-	-	-
60.	▶ TL.60.01.Z0	20	-	-	48	5.8
65.	▶ TL.65.01.Z0	27	-	-	64	6.5
70.	▶ TL.70.01.Z0	27	-	-	64	6.5
85.	▶ TL.85.01.Z0	30	-	-	64	6.5
85. (R 240)	▶ Alternative: standard mounting bracket	-	-	-	-	-
100.	▶ TL.100.01.Z0	30	-	-	64	6.5
125.	▶ Alternative: standard mounting bracket	-	-	-	-	-

TL.30.01.Z0 TL.40.01.Z0 TL.60.01.Z0 TL.65.01.Z0 TL.70.01.Z0 TL.85.01.Z0 TL.100.01.Z0

