 


# triflex® R | Serie TRLF | Lieferprogramm

## Schnelles Befüllen von dicken Schläuchen und Leitungen



TRLF


▶748



### e-ketten® | Serie TRLF | Leichte Variante mit Schnappverschluss

Art. Nr.	Bi1	Ba	R	d1	Teilung	Glieder/	TRLF
e-ketten®	[mm]	[mm]	[mm]	[mm]	[mm]	[m]	[kg/m]
TRLF. 65. 100 .0	24,4	70,2	100	22	23,1	44	≈ 0,79
TRLF. 85. 135 .0	32,8	94,5	135	30	30,6	33	≈ 1,45
TRLF. 100.145 .0 <sup>1)</sup>	37,5	108	145	35,5	34,5	29	≈ 1,90
TRLF. 125.182 .0	46,8	135	182	44,5	44,1	23	≈ 4,13

### Einbaumaße

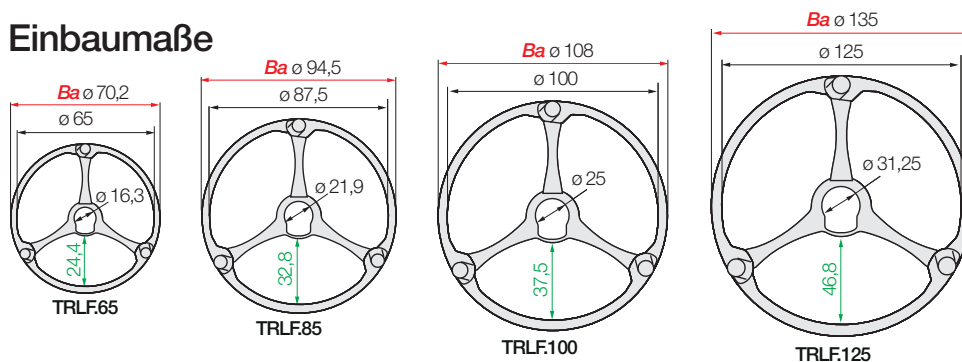

Schnappverschluss zum schnellen Öffnen, igus® Video online

▶ [www.igus.de/TRLF](http://www.igus.de/TRLF)