





Polymer - locking

- One-piece mounting bracket
- Corrosion-resistant
- Available preassembled
- Inner and outer attachment possible
- Available with or without integrated strain relief tiwrap plates

Moving end with bore
(outer link) 117...1P(Z)

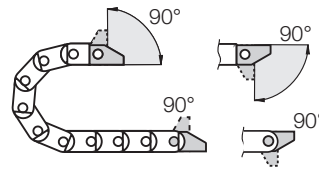


117...2P(Z) Fixed end
with pin (inner link)

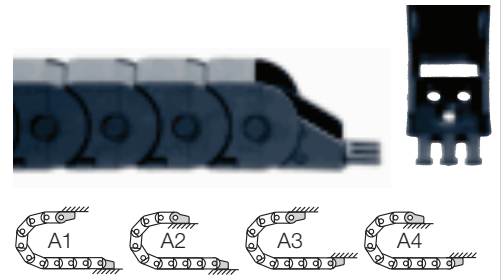


Possible installation conditions for assembled mounting brackets ▶ Order example "preassembled" below

117...1P(Z)
Moving end

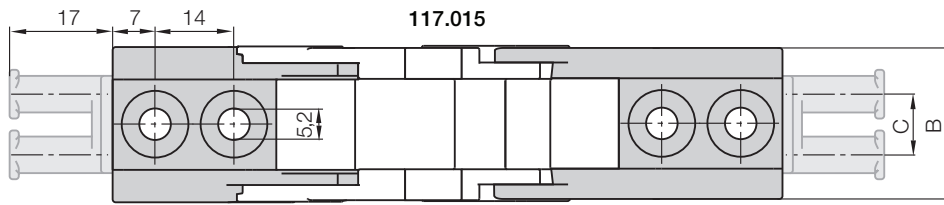


117...2P(Z)
Fixed end

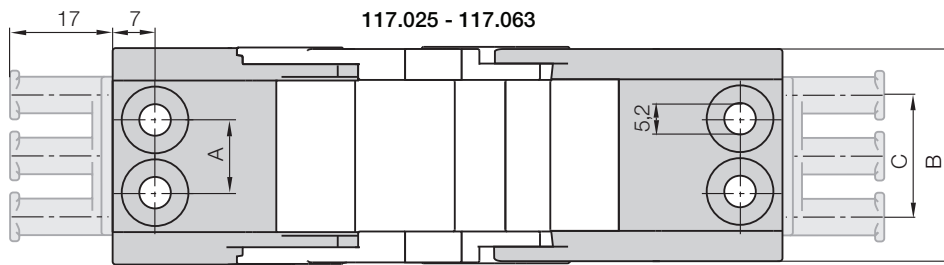

Dimensions and order configurations

Strain relief is possible on the moving end and/or the fixed end.

Part No. structure

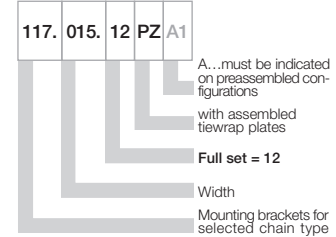

For E-chain®	Part No. full set with tiwrap plate	Part No. full set without tiwrap plate	Number of teeth	Dim. A [mm]	Dim. B [mm]	Dim. C [mm]
R17.015.	▶ 117.015. 12 PZ	117.015. 12 P	2	-	25,7	10
R17.025.	▶ 117.025. 12 PZ	117.025. 12 P	3	12	35,7	20
R17.063.	▶ 117.063. 12 PZ	117.063. 12 P	6	48	73,7	50

Full set, for both ends:

117. 015. 12 PZ +tiwrap plate

Single-part order:

117. 015. 1 PZ +tiwrap plate

Mounting bracket with bore

117. 015. 2 PZ +tiwrap plate

Mounting bracket with pin

For the preassembled mode please add the index A1... A4 Example: 117.015. 12 PZ A1



Quicksnap - the complete, detachable mounting unit, available upon request



Quickfix - mounting bracket with dowel, available upon request

Additional Features

Phone +49- (0) 22 03-96 49-800
Fax +49- (0) 22 03-96 49-222

