



igubal® R...M | Kugelkalotten | mm

Low Cost – iglidur® R; sehr verschleißfestes Material



igubal®-Kugelkalotten

mm R...M/X...M

Telefon (0 22 03) 96 49-145
Telefax (0 22 03) 96 49-334

igus® GmbH
51147 Köln

Internet: www.igus.de
E-Mail: info@igus.de

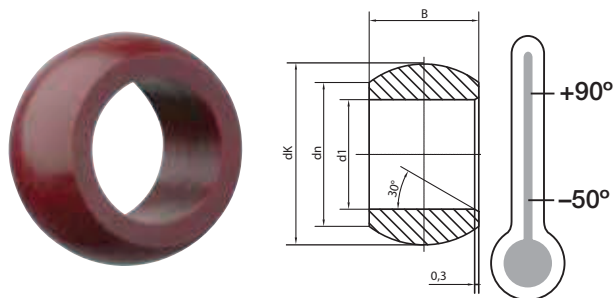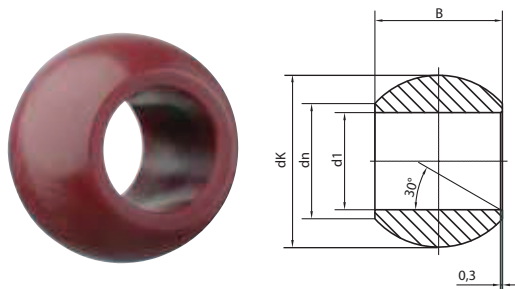

Abmessungen [mm]

igubal®-Kugelkalotten RKM

Bestellnummer	d1 E10	dn	dK	B
RKM-10-14	10,00	12,90	19,00	14,00



Abmessungen [mm]

igubal®-Kugelkalotten REM

Bestellnummer	d1 E10	dn	dK	B
REM-05-06	5,00	8,00	10,20	6,00
REM-06-06	6,00	8,00	10,20	6,00
REM-08-08	8,00	10,00	13,20	8,00
REM-10-09	10,00	13,00	16,10	9,00
REM-12-10	12,00	15,00	18,10	10,00

igubal® X...M | Kugelkalotten | mm

Hochtemperaturen – iglidur® X; sehr verschleißfestes Material

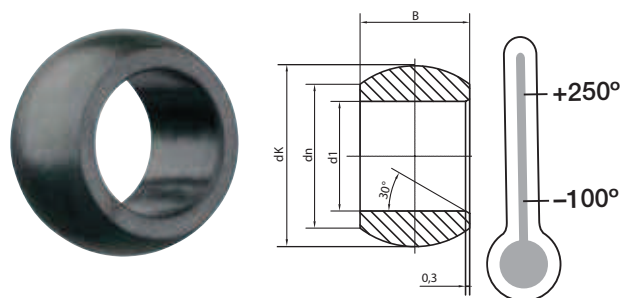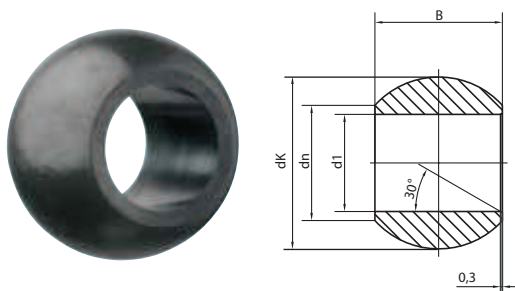

Abmessungen [mm]

igubal®-Kugelkalotten XKM

Bestellnummer	d1 E10	dn	dK	B
XKM-10-04	10,00	12,90	19,10	14,00

Abmessungen [mm]

igubal®-Kugelkalotten XEM

Bestellnummer	d1 E10	dn	dK	B
XEM-05-06	5,00	8,00	10,30	6,00
XEM-06-06	6,00	8,00	10,20	6,00
XEM-08-08	8,00	10,00	10,30	8,00
XEM-10-09	10,00	13,00	16,10	9,00
XEM-12-10	12,00	15,00	18,10	10,00