


# Distributor racks

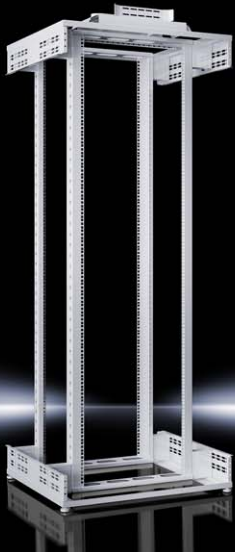

System accessories Page 11 19" installation Page 21 TE 8000 Page 6

## Benefits:

- Optimum accessibility from all sides during assembly and installation
- Unrestricted airflow, due to the open design
- Standard cable trays in the roof area for larger quantities of cables
- The distance between attachment levels is infinitely variable

## Material:

- Sheet steel

## Surface finish:

- Powder-coated

## Colour:

- RAL 7035


## Supply includes:

- Self-supporting mounting frame, with 482.6 mm (19") mounting level front and rear
- Roof-plate prepared for accommodating cable organisers
- Open base frame with 2 punched sections with mounting flanges for individual configuration fitted in the width
- 4 levelling feet, M10 (supplied loose)

Please observe the product-specific scope of supply.

## Further technical information:

Available on the Internet

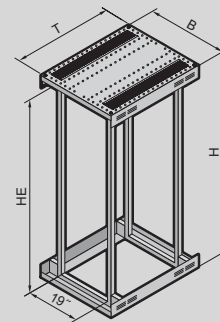

## TE 8000 open

Units U	Packs of	42	42	Page
Width (B) mm		600	800	
Height (H) mm		2000	2000	
Depth (T) mm		1000	1000	
Distance between prefitted 482.6 mm (19") levels mm		745	745	
Free mounting space to the 482.6 mm (19") level, front/rear mm		80 / 130	80 / 130	
Max. load capacity (static) per enclosure kg		700	700	
<b>Model No.</b>	1 pc(s).	<b>7888.940</b>	<b>7888.944</b>	
<b>Product-specific scope of supply</b>				
Side panels, lockable, including security lock 3524 E	2 pc(s).	■	–	
Baying kit	4 pc(s).	–	■	
<b>Accessories</b>				
Cable organiser	4 pc(s).	7888.950	7888.950	
Component shelf, static installation	1 pc(s).	5501.665	5501.665	18
Component shelf, pull-out	1 pc(s).	5501.685	5501.685	17
Slide rails, heavy-duty	2 pc(s).	7063.740	7063.740	19
Slide rails, depth-variable	2 pc(s).	5501.480	5501.480	19
Cable clamp rails, depth-variable	4 pc(s).	7858.162	7858.162	16
Cable clamp rails	4 pc(s).	7828.062	7828.062	16
C rails	4 pc(s).	7828.060	7828.060	16
Cable route	1 pc(s).	7000.685	7000.685	18
Cable duct	1 pc(s).	–	5502.105	20
Cable routing bars, 482.6 mm (19") attachment	4 pc(s).	7111.224	7111.224	20
Shunting ring	4 pc(s).	–	7220.600	20
Cable management panel		see page	see page	21