
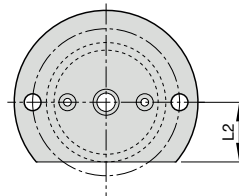


2


### Kegeldistanzen VW-Norm 39V 1168

### Locating cone VW-norm 39V 1168


### Cônes de distance Norme de VW 39V 1168

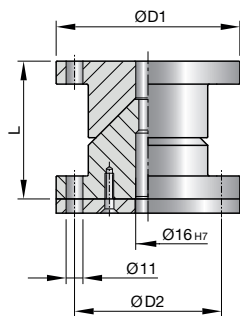

Type 2

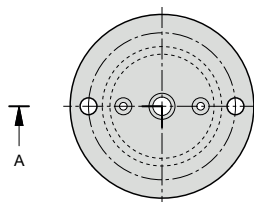

Type 1

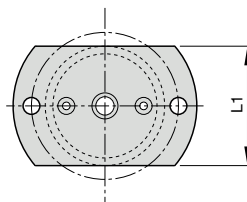

Type 3

SN43-

Mat.: ST

SN43-Type-D1



Type	D1	L	D2	L1	L2
1	100	80	76	-	-
	120	90	96	-	-
2	100	80	76	-	29
	120	90	96	-	39
3	100	80	76	58	-
	120	90	96	78	-

