


## SERIES 62



**“TR-ROLL” POLYURETHANE WHEELS,  
ALUMINIUM CENTRE,  
FIXED BRACKET TYPE EEG HD**

### Wheel description

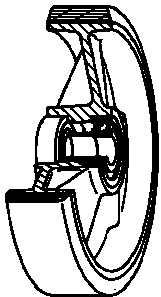


**Tread:** “TR-ROLL” polyurethane, hardness 75 Shore A.

**Centre:** aluminium.

**Hub:** the housing is obtained by moulding and contains ball bearings series Z.

### Bracket description

**Heavy Duty bracket type EEG (max. load capacity 2000 daN)**

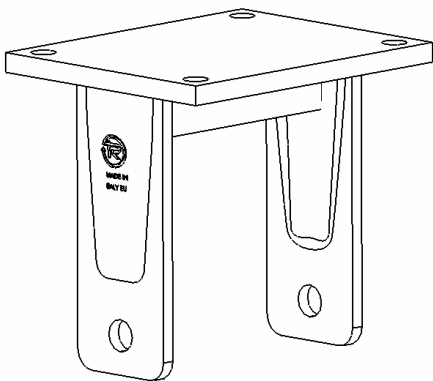

The bracket is made by a steel forged fixing plate with 4 holes, by two steel drawn sides and by a steel central stiffening. These elements are bounded by welding and properly protected against oxydation.