


SERIES 62



**“TR-ROLL” POLYURETHANE WHEELS,
ALUMINIUM CENTRE,
SWIVEL TOP PLATE BRACKET TYPE EP**

Wheel description

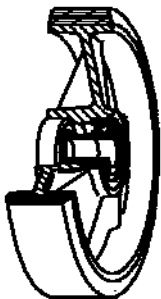


Tread: “TR-ROLL” polyurethane, hardness 75 Shore A.

Centre: aluminium.

Hub: the housing is obtained by moulding and contains ball bearings series Z.

Bracket description

Extra-heavy duty bracket type EP (max. load capacity 1600 daN)

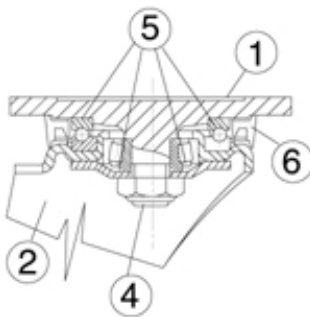

1) **Plate:** electrolytically galvanised forged steel

2) **Fork:** electrolytically galvanised steel plate

4) **Central pin:** solid with the machined plate

5) **Swivel actions:** axial ball bearing and taper roller bearing

6) **Dust seal:** orange polyethylene

Finish: white galvanisation

Fitting top plate