


## SERIES 62



**“TR-ROLL” POLYURETHANE WHEELS,  
ALUMINIUM CENTRE,  
SWIVEL TOP PLATE BRACKET TYPE M**

### Wheel description

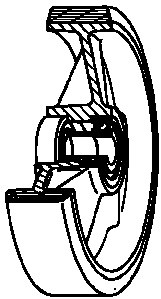


**Tread:** “TR-ROLL” polyurethane, hardness 75 Shore A.

**Centre:** aluminium.

**Hub:** the housing is obtained by moulding and contains ball bearings series Z.

### Bracket description

**Medium duty racket type M (max. load capacity 500 daN)**

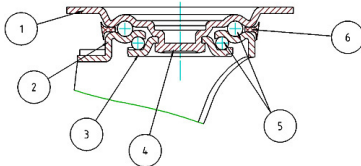

- 1) **Plate:** electrolytically galvanised steel plate
  - 2) **Fork:** electrolytically galvanised steel plate
  - 3) **Ball Racing Ring:** electrolytically galvanised steel plate
  - 4) **King Pin:** incorporated in top plate and cold riveted
  - 5) **Swivel actions:** double ring of greased balls
  - 6) **Dust seal:** blue polyethylene
- Finishing:** electrolytic galvanisation  
**Fitting:** top plate