


## SERIES 62



**“TR-ROLL” POLYURETHANE WHEELS,  
ALUMINIUM CENTRE,  
FIXED BRACKET TYPE NL**

---

### *Wheel description*

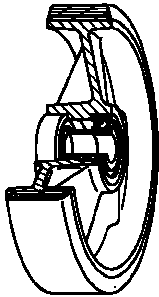

**Tread:** “TR-ROLL” polyurethane, hardness 75 Shore A.


**Centre:** aluminium.

**Hub:** the housing is obtained by moulding and contains ball bearings series Z

---

### *Bracket description*

**Standard duty bracket type NL (max. load capacity 400 daN)**

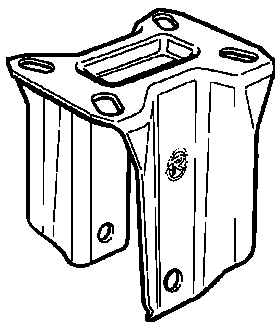

The bracket is made by an electrolytically galvanised steel fork.