


SERIES 62



**“TR-ROLL” POLYURETHANE WHEELS,
ALUMINIUM CENTRE,
SWIVEL TOP PLATE BRACKET TYPE NL**

Wheel description

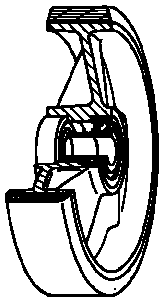


Tread: “TR-ROLL” polyurethane, hardness 75 Shore A.

Centre: aluminium.

Hub: the housing is obtained by moulding and contains ball bearings series Z.

Bracket description

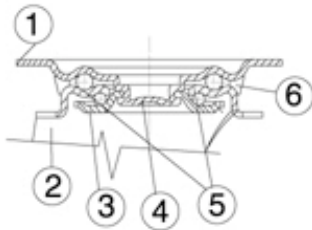

Standard duty bracket type NL (max. carrying capacity 400 daN)

1) **Plate:** electrolytically galvanised steel plate

2) **Fork:** electrolytically galvanised steel plate

3) **Ball Racing Ring:** electrolytically galvanised steel plate

4) **King Pin:** incorporated in top plate and cold riveted

5) **Swivel actions:** double ring of greased balls

6) **Dust seal:** orange polyethylene

Finishing: electrolytic galvanisation

Fitting: top plate