


## SERIES 63



### VULKOLLAN® WHEELS, CAST IRON CENTRE, FIXED BRACKET TYPE EEG EHD

#### Wheel description

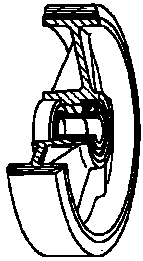


**Tread:** Vulkollan® polyurethane tread; hardness 93 +/-2 Shore A

**Centre:** cast iron.

**Hub:** the housing is obtained by moulding and turning and contains ball bearings series Z

#### Bracket description

##### EEG Extra Heavy Duty bracket (max. load capacity 3500 daN)

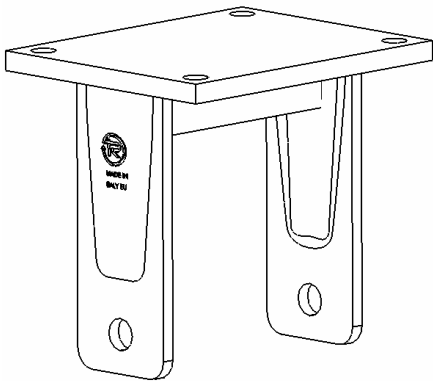

The bracket is made by a steel forged fixing plate with 4 holes, by two steel drawn sides and by a steel central stiffening. These elements are bounded by welding and properly protected against oxydation.