


SERIES 63



VULKOLLAN® WHEELS, CAST IRON CENTRE, SWIVEL TOP PLATE BRACKET TYPE EEG EHD

Wheel description

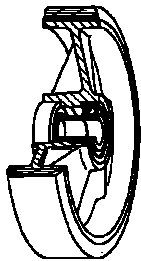


Tread: Vulkollan® polyurethane tread; hardness 93 +/-2 Shore A

Centre: cast iron.

Hub: the housing is obtained by moulding and turning and contains ball bearings series Z

Brake description

EEG Extra Heavy Duty bracket (max. load capacity 3500 daN)

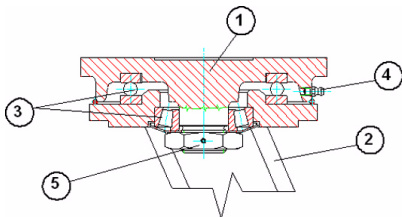

- 1) **Plate:** forged steel with integrated pin
 - 2) **Fork:** drawn sides electrowelded to the flange
 - 3) **Swivel actions:** axial ball bearing and taper roller bearing
 - 4) **Lubricator**
 - 5) **Nut anti-loosening system**
- Finish:** dark green powder coating
Fitting: top plate