


SERIES 63



VULKOLLAN® WHEELS, CAST IRON CENTRE, FIXED BRACKET TYPE EEG HD

Wheel description

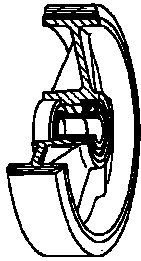


Tread: Vulkollan® polyurethane tread; hardness 93 +/-2 Shore A

Centre: cast iron.

Hub: the housing is obtained by moulding and turning and contains ball bearings series Z

Bracket description

Heavy Duty bracket type EEG (max. load capacity 2000 daN)

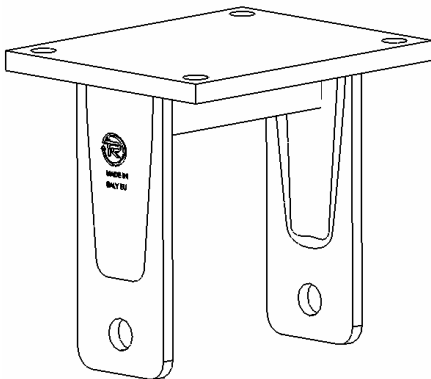

The bracket is made by a steel forged fixing plate with 4 holes, by two steel drawn sides and by a steel central stiffening. These elements are bounded by welding and properly protected against oxydation.