


SERIES 63



VULKOLLAN® WHEELS, CAST IRON CENTRE, SWIVEL TOP PLATE BRACKET TYPE EEG MHD

Wheel description

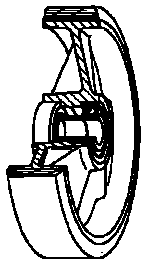


Tread: Vulkollan® polyurethane tread; hardness 93 +/-2 Shore A

Centre: cast iron.

Hub: the housing is obtained by moulding and turning and contains ball bearings series Z

Bracket description

EEG Medium Heavy Duty bracket (max. load capacity 900 daN)

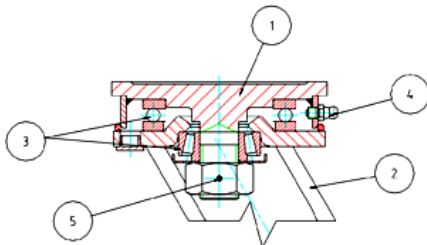

1) **Plate:** forged steel with integrated pin

2) **Fork:** drawn sides electrowelded to the flange

3) **Swivel actions:** axial ball bearing and taper roller bearing

4) **Lubricator**

5) **Nut anti-loosening system**

Finish: electrolytic galvanisation

Fitting: top plate