


SERIES 63



VULKOLLAN® WHEELS, CAST IRON CENTRE, SWIVEL TOP PLATE BRACKET TYPE P

Wheel description

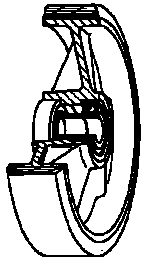


Tread: Vulkollan® polyurethane tread; hardness 93 +/-2 Shore A

Centre: cast iron.

Hub: the housing is obtained by moulding and turning and contains ball bearings series Z

Bracket description

Heavy duty bracket type P (max. carrying capacity 750 daN)

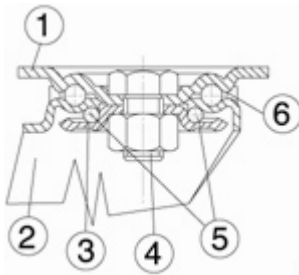

1) **Plate:** electrolytically galvanised steel plate

2) **Fork:** electrolytically galvanised steel plate

3) **Ball Racing Ring:** electrolytically galvanised steel plate

4) **King Pin:** steel screw class 8.8 and nut

5) **Swivel actions:** double ring of greased balls

6) **Dust seal:** red polyamide

Finishing: yellow galvanisation

Fitting: top plate