


## SERIES 65



**“TR” POLYURETHANE WHEELS,  
CAST IRON CENTRE,  
SWIVEL TOP PLATE BRACKET TYPE “EP”**

### Wheel description

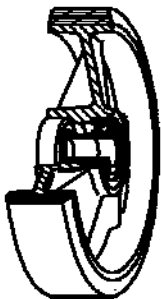


**Tread:** “TR” polyurethane, hardness 93 +/- 5 Shore A, excellent rolling resistance and elasticity, good resistance to wear and to tearing.

**Centre:** cast iron.

**Hub:** the housing is obtained by turning and contains ball bearings series Z.

### Bracket description

**Standard duty bracket type EP (max. carrying capacity 1600 daN)**

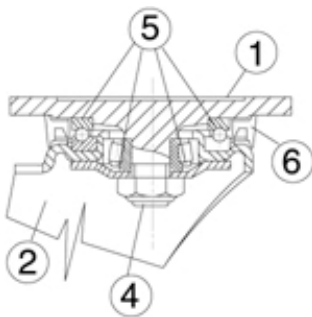

1) **Plate:** green galvanised steel plate

2) **Fork:** green galvanised steel plate

4) **King pin:** solid with the machined plate

5) **Swivel actions:** axial ball bearing anche tapered roller bearing

6) **Dust seal:** orange polyethylene

**Finishing:** white galvanisation

**Fitting:** top plate