


SERIES 65HT



**WHEELS IN THICK “TR” POLYURETHANE,
ALUMINIUM CENTRE,
SWIVEL TOP PLATE BRACKET TYPE P**


Wheel description

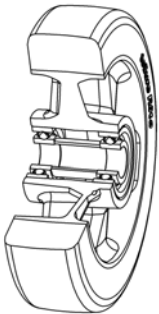

Tread: “TR” polyurethane, hardness 95 Shore A, very thick and rounded profile.
Centre: aluminium.
Hub: the housing is obtained by moulding and contains ball bearings series Z

Bracket description

Medium-heavy duty bracket type P (max. carrying capacity 750 daN)

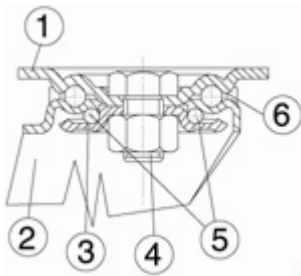

- 1) **Plate:** electrolytically galvanised steel plate
 - 2) **Fork:** electrolytically galvanised steel plate
 - 3) **Ball Racing Ring:** electrolytically galvanised steel plate
 - 4) **King Pin:** steel screw class 8.8 and nut
 - 5) **Swivel actions:** double ring of greased balls
 - 6) **Dust seal:** red polyamide
- Finishing:** yellow galvanisation
Fitting: top plate