


## SERIES 72



**SIGMA ELASTIC RUBBER WHEELS  
CAST IRON CENTRE  
SWIVEL TOP PLATE BRACKET TYPE EE MHD**

### Wheel description

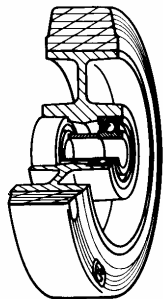


**Tread:** Sigma Elastic rubber tread; hardness 70 +/-3 Shore A.

**Centre:** cast iron.

**Hub:** Hub: The housing is obtained by moulding and turning and contains ball bearings series Z.

### Bracket description

**Bracket EE Medium Heavy Duty (max. load capacity 900 daN)**

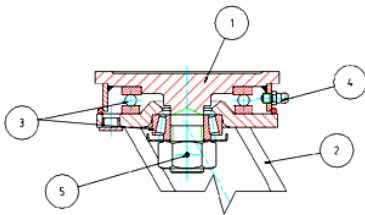

- 1) **Plate:** forged steel with integrated pin
  - 2) **Fork:** drawn sides electrowelded to the flange
  - 3) **Swivel actions:** axial ball bearing and taper roller bearing
  - 4) **Lubricator**
  - 5) **Nut anti-loosening system**
- Finish:** electrolytic galvanisation  
**Fitting** top plate