


## SERIES 72



### SIGMA ELASTIC RUBBER WHEELS CAST IRON CENTRE FIXED BRACKET TYPE EP

#### Wheel description

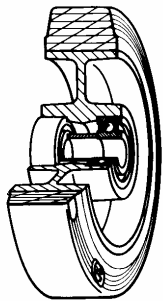


**Tread:** Sigma Elastic rubber tread; hardness 70 +/-3 Shore A.

**Centre:** cast iron.

**Hub: Hub:** The housing is obtained by moulding and turning and contains ball bearings series Z.

#### Bracket description

**Extra-heavy duty bracket type EP (max. load capacity 1600 daN)**

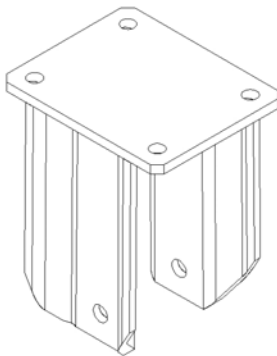

The bracket is made by a white galvanised steel fork.