


## SERIES 72



### SIGMA ELASTIC RUBBER WHEELS CAST IRON CENTRE SWIVEL TOP PLATE BRACKET TYPE P

#### Wheel description

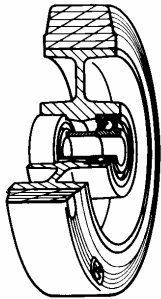


**Tread:** Sigma Elastic rubber tread; hardness 70 +/-3 Shore A.

**Centre:** cast iron.

**Hub:** Hub: The housing is obtained by moulding and turning and contains ball bearings series Z.

#### Bracket description

**Medium-heavy duty bracket type P (max. carrying capacity 750 daN)**

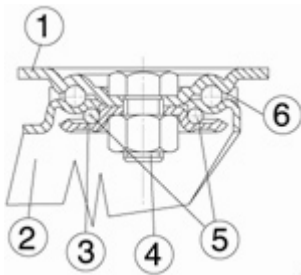

1) **Plate:** electrolytically galvanised steel plate

2) **Fork:** electrolytically galvanised steel plate

3) **Ball Racing Ring:** electrolytically galvanised steel plate

4) **King Pin:** steel screw class 8.8 and nut

5) **Swivel actions:** double ring of greased balls

6) **Dust seal:** red polyamide

**Finishing:** yellow galvanisation

**Fitting:** top plate