


## SERIES 72



**SIGMA ELASTIC RUBBER WHEELS  
ALUMINIUM CENTRE  
FIXED BRACKET TYPE EEG MHD**

### Wheel description

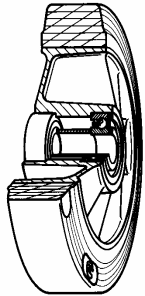


**Tread:** Sigma Elastic rubber tread; hardness 70 +/-3 Shore A.

**Centre:** aluminium.

**Hub:** The housing is obtained by moulding and contains ball bearings series Z.

### Bracket description

**Medium Heavy Duty bracket type EEG (max. load capacity 900 daN)**

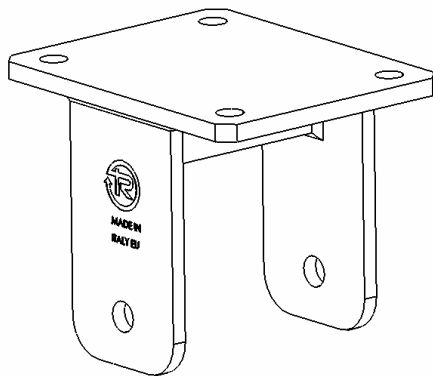

The bracket is made by a steel forged fixing plate with 4 holes, by two steel drawn sides and by a steel central stiffening. These elements are bounded by welding and properly protected against oxydation by electrolytically galvanisation.