


## SERIES 72



### SIGMA ELASTIC RUBBER WHEELS ALUMINIUM CENTRE SWIVEL TOP PLATE BRACKET TYPE "M"

#### Wheel description

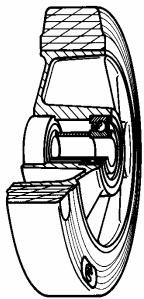


**Tread:** Sigma Elastic rubber tread; hardness 70 +/-3 Shore A.

**Centre:** aluminium.

**Hub:** The housing is obtained by moulding and contains ball bearings series Z.

#### Bracket description

**Medium duty bracket type M (max. carrying capacity 500 daN)**

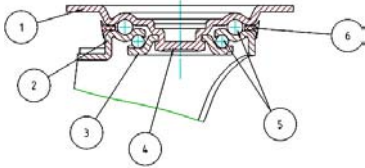

- 1) **Plate:** electrolytically galvanised steel plate
  - 2) **Fork:** electrolytically galvanised steel plate
  - 3) **Ball Racing Ring:** electrolytically galvanised steel plate
  - 4) **King Pin:** incorporated in top plate and cold riveted
  - 5) **Swivel actions:** double ring of greased balls
  - 6) **Dust seal:** blue polyethylene
- Finishing:** electrolytic galvanisation  
**Fitting:** top plate