


## SERIES 82



### PNEUMATIC WHEELS COUNTRY PROFILE POLYPROPYLENE CENTRE SWIVEL TOP PLATE BRACKET TYPE "NL"


#### Wheel description

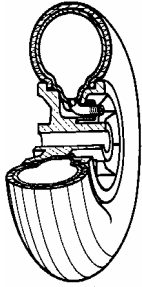

- Tread:** Pneumatic tyred wheels with country profile and 4 plies; working pressure: 2 bar.  
**Centre:** polypropylene.  
**Hub:** the hub is available with plain bearing and with roller bearing.

#### Bracket description

**Standard duty bracket type NL (max. carrying capacity 400 daN)**

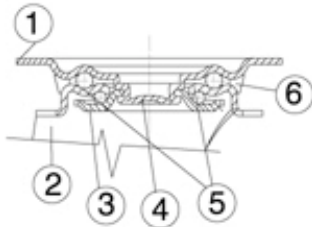

- 1) **Plate:** electrolytically galvanised steel plate
  - 2) **Fork:** electrolytically galvanised steel plate
  - 3) **Ball Racing Ring:** electrolytically galvanised steel plate
  - 4) **King Pin:** incorporated in top plate and cold riveted
  - 5) **Swivel actions:** double ring of greased balls
  - 6) **Dust seal:** orange polyethylene
- Finishing:** electrolytic galvanisation  
**Fitting:** top plate