


SERIES 60



**“TR” POLYURETHANE WHEELS,
POLYAMIDE 6 CENTRE,
SWIVEL BRACKET WITH STEM TYPE “NL”**

Wheel description

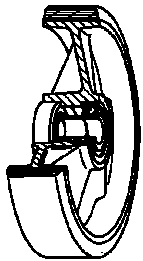


Tread: injection polyurethane tread, hardness 55 Shore D; excellent rolling resistance and elasticity, highly resistant to wear and to tearing.

Centre: polyamide 6.

Hub: the hub is available with plain bearing and with roller bearing..

Bracket description

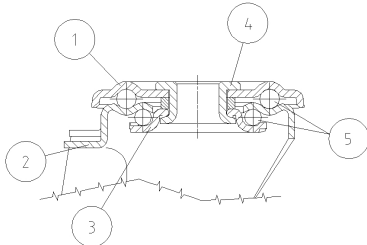

Standard duty bracket type NL (max. carrying capacity 400 daN)

- 1) **Plate:** electrolytically galvanised steel plate
 - 2) **Fork:** electrolytically galvanised steel plate
 - 3) **Ball Racing Ring:** electrolytically galvanised steel plate
 - 4) **King Pin:** incorporated in top plate and cold riveted
 - 5) **Swivel actions:** double ring of greased balls
- Finishing:** electrolytic galvanisation
Fitting: stem